


FENDA table lamp base I E27

Indoor table lamp in white without shade

The white FENDA table lamp base from the FENDA Mix & Match system makes easy combination with FENDA lamp shades possible to suit the ambience, or with colour accents in the latest fashionable colours. With its built-in E27 socket, the luminaire is suitable for both LED lamps and energy-saving lamps. The FENDA lamp base is delivered with a lead complete with a mains plug and an integrated switch. The product is ready to be directly connected to the 230V supply.

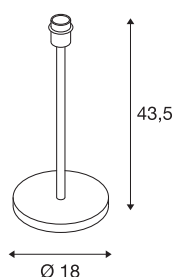

TECHNICAL DATA

Item no.:	1003030
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	43.5 cm
Diameter	18 cm
Net weight	2.074 kg
Gross weight	2.703 kg
IP Code	IP 20
Safety class	II
Impact resistance class	IK03
Impact resistance	0,35 Joule
Assembly	Mobile
Wattage	60 W
Color	white
Maximum ambient temperature	40 °C
BIG WHITE Page	104

Recommended lamp

1005302	A60 E27 , white LED light, 13.2W 2700K CRI90 220°
1005303	A60 E27 , transparent LED light, 7.5W 2700K CRI90 320°
1005304	A60 E27 , Frosted LED light, 7.5W 2700K CRI90 320°
1005318	A60 E27 RGBW smart , white / milky LED light, 9W CRI90 230°