




FENDA floor stand base I E27

Indoor floor stand in white without shade

We are offering a new basic design for living room lights with the FENDA floor stand. The white base makes combination with various shades from the FENDA series possible. Prepared for accommodating LED or energy-saving lamps with an E27 socket, the FENDA is ready for direct connection to the 230V mains power supply. In addition, a switch is included located in the connection lead.

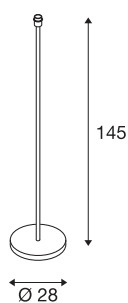

TECHNICAL DATA

Item no.:	1003031
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	145 cm
Diameter	28 cm
Net weight	5.621 kg
Gross weight	6.694 kg
IP Code	IP 20
Safety class	II
Impact resistance class	IK03
Impact resistance	0,35 Joule
Assembly	Mobile
Wattage	60 W
Color	white
Maximum ambient temperature	40 °C
BIG WHITE Page	104

Recommended lamp

1005301	A60 E27 , white LED light, 9W 2700K CRI90 220°
1005303	A60 E27 , transparent LED light, 7.5W 2700K CRI90 320°
1005304	A60 E27 , Frosted LED light, 7.5W 2700K CRI90 320°
1005318	A60 E27 RGBW smart , white / milky LED light, 9W CRI90 230°