




## FENDA

table lamp, lamp base, A60, black, without shade, max. 60W

The FENDA table lamp base comes in black and is from the FENDA Mix & Match system allowing it to be easily combined with FENDA lamp shades to suit the ambience or with colour accents in the current trendy colours. With its in-built E27 socket, the luminaire is suitable for both LED and energy-saving lamps. The FENDA lamp base is delivered with a lead complete with a mains plug and an integrated switch. The product is ready to be directly connected to the 230V supply.

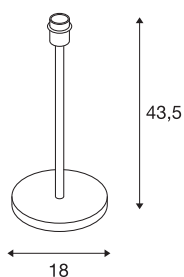

## TECHNICAL DATA

Item no.:	155780
Socket	E27
Number of sockets	1
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	43.5 cm
Diameter	18 cm
Net weight	1.988 kg
Gross weight	2.636 kg
IP Code	IP 20
Safety class	II
Impact resistance class	IK03
Impact resistance	0,35 Joule
Assembly	Mobile
Wattage	60 W
Color	black
Maximum ambient temperature	40 °C
BIG WHITE Page	104

## Recommended lamp

1005302	A60 E27 , white LED light, 13.2W 2700K CRI90 220°
1005304	A60 E27 , Frosted LED light, 7.5W 2700K CRI90 320°