




ROX CEILING OUT

QPAR11, outdoor ceiling light, brushed aluminium, max. 50W, IP44

The puristic ceiling light of the ROX series is made from brushed aluminium and glass, which covers the lamp. It is suitable for use outdoors thanks to its IP44 protection class. The electrical connection is made directly to the 230V mains supply. The ROX series also includes wall lights as well as floor stands with different sockets and can therefore be used universally.

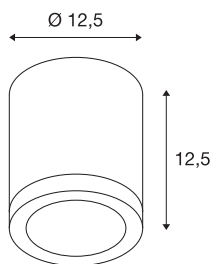

TECHNICAL DATA

Item no.:	1000332
Socket	GU10
Lamp	QPAR111
Number of sockets	1
Lamps included	No
Primary nominal voltage	220-240V ~50/60Hz mA/V
Height	12.5 cm
Diameter	12.5 cm
Net weight	0.849 kg
Gross weight	0.967 kg
IP Code	IP 44
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Wattage	50 W
Color	aluminium
BIG WHITE Page	679

Recommended lamp

1005274	QPAR111 GU10 , transparent LED light, 8W 2700K CRI90 38°
1005282	QPAR111 GU10 , silver LED light, 12.5W 4000K CRI90 30°
1005291	QPAR111 GU10 , silver LED light, 7W 2700K CRI-90 25°
1005292	QPAR111 GU10 , silver LED light, 7W 3000K CRI-90 25°