




DIO FLEX PLATE

WL, LED indoor display fitting, white, 4000K

Adjustable 240V display fitting for wall mounting of the DIO FLEX PLATE series, whereby the canopy and lamp head are connected via a flexible arm. Because of the switch that is fitted, the individually adjustable luminaire is suitable for many applications. The luminaire is connected directly to the 230V mains supply. An LED version is available as an alternative.

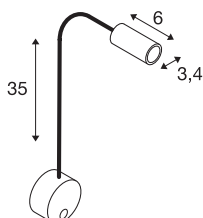

TECHNICAL DATA

Item no.:	1002119
Primary nominal voltage	100-240V ~50/60Hz mA/V
Secondary power / secondary voltage	350mA
Length	49.8 cm
Diameter	9 cm
Net weight	0.504 kg
Gross weight	0.58 kg
IP Code	IP 20
Safety class	I
Assembly	Surface
Assembly details	Wall
Wattage	1.9 W
Lumen	100 lm
Colour temperature	4000 Kelvin
Beam angle	45 °
Color	white
CRI	80
LXXBXX data	L70B50
Minimum ambient temperature	-20 °C
Maximum ambient temperature	45 °C
BIG WHITE Page	228

Light Source

916340

