


EMERGENCY EXIT SIGN

M19

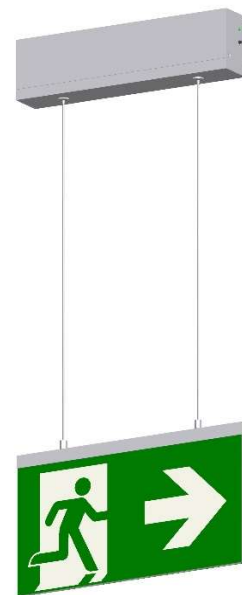


Technical Data

Viewing distance	30 m	IP rating	IP 40
Mounting	Ceiling surface wire suspension	IK rating	IK 06
Housing material	Aluminum	Light source	LED
Housing colour	Silver	Colour temperature	6500 K
Insulation class	I	Luminance	500 or 50 cd/m2, selectable

	Self-contained	Centrally supplied
Rated voltage	220-240 V AC, 50/60 Hz	220-240 V AC, 50/60 Hz 180-300 V DC
Rated wattage	3.1W (500 cd/m2), 0.5W (50 cd/m2)	3.8 W
Mode of operation	Maintained or non-maintained, selectable	Maintained
Emergency duration	1/2/3/8 h, selectable	-
Battery	LiFePO4 3.2 V/1.5 Ah	Central battery
Test system	Automatic, manual	-
Ambient temp.	0 °C to +40 °C	-10 °C to +40 °C

Dimensions

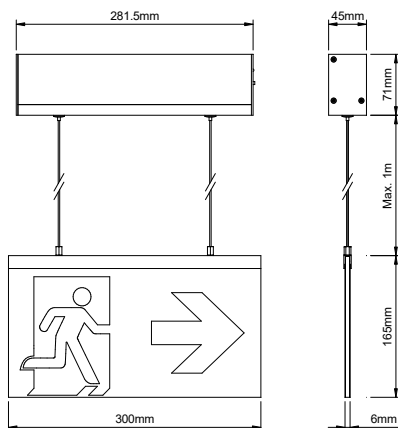

Article number	Type	Weight
M19001	M19-30 LFP Self-contained	0.92 kg
M19002	M19-30 CS Central battery	0.87 kg