
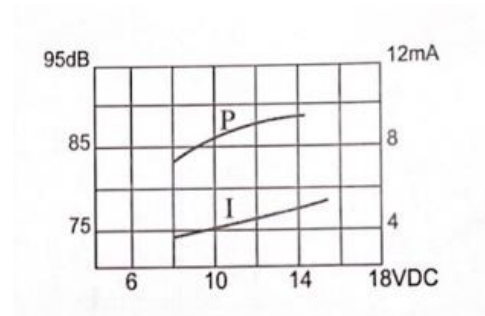


Data Sheet

Piezo buzzer, pin type

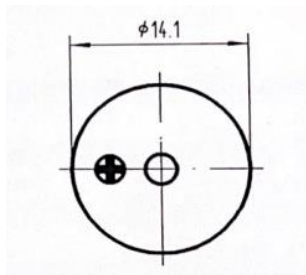

Rated voltage	12VDC
Operating voltage	1.5-16VDC
Max. current	8mA at 12VDC
Min. S.P.L	85dB at 12VDC/10cm
Resonant Frequency	4.0±0.5Khz
Tone nature	Continuous
Grid pitch	7.5 mm
Color	Black
Housing materials	PBT
Weight	2g
Operation Temperature	-25°C to +50 °C
Storage Temperature	-25 °C to +50 °C