
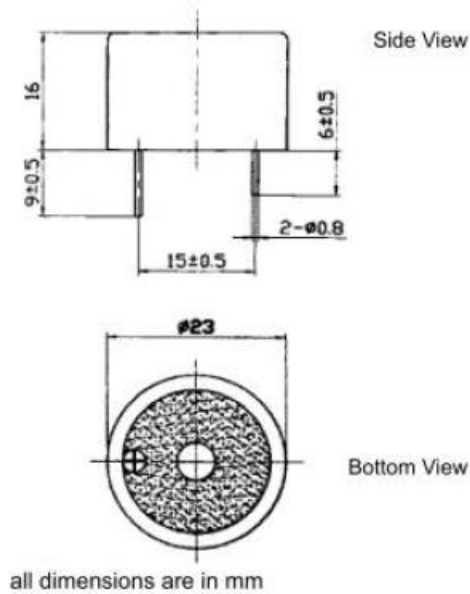


Data Sheet

Piezo buzzer (Pin type) 85 dB

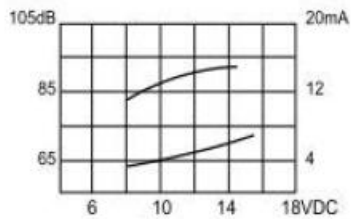

Rated voltage: 12 V

Operating voltage: 8-24 VDC

Max. rated current: 15mA at 12VDC

Noise development: 85 dB at 12VDC/30 cm

Key: Continuous tone

Resonant frequency: 2.9 ± 0.5 KHz

Housing material: PC

Operating temperature: -20°C to 80°C

Storage temperature: -30°C to 100°C