


## Data Sheet

### Push on Turn reset switch

Version 10/23

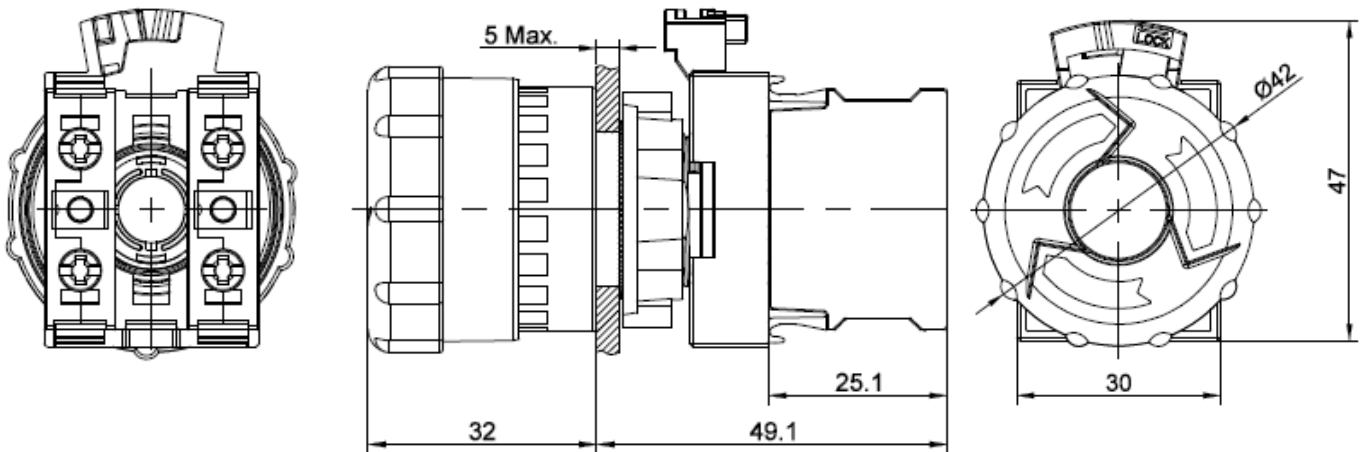

### Specification

Mounting diameter.....	22 mm
Head shape.....	Round head
Head colour.....	Red
Operation type.....	Push on turn reset
Contact structure.....	1NO1NC
Switch rating.....	Ie/Ue: 5A/250AC
Terminal.....	Screw terminal
Operating and storage temperature.....	-25 to +55°C
Operating and storage humidity.....	45 to 85 % RH
IP rating.....	IP40
Mechanical lifetime.....	200,000 cycles
Electrical lifetime.....	50,000 cycles
Dielectric strength.....	3000V, AC 50HZ, 1 minute
Insulation resistance.....	≥ 100MΩ