


## Data Sheet

### Push on turn reset switch

Version 10/23

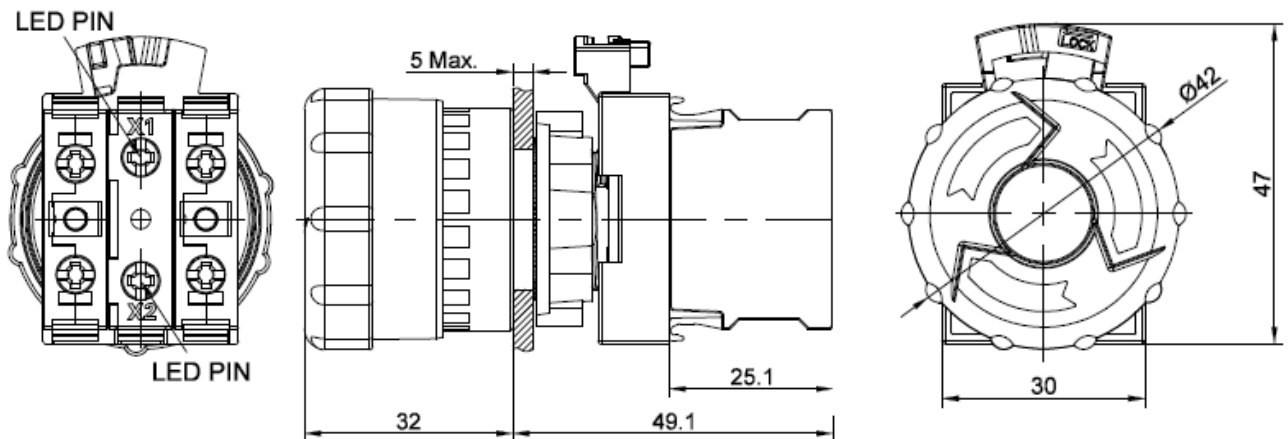

### Specification

|                                         |                          |
|-----------------------------------------|--------------------------|
| Mounting diameter.....                  | 22 mm                    |
| Head shape .....                        | Round head               |
| LED colour.....                         | Red                      |
| LED voltage.....                        | 12V-24V                  |
| Operation type.....                     | Push on turn reset       |
| Contact structure .....                 | 1NO1NC                   |
| Switch rating.....                      | Ie/Ue: 5A/250AC          |
| Terminal .....                          | Screw terminal           |
| Operating and storage temperature ..... | -25 to +55°C             |
| Operating and storage humidity .....    | 45 to 85 % RH            |
| IP rating .....                         | IP40                     |
| Mechanical lifetime.....                | 200,000 cycles           |
| Electrical lifetime .....               | 50,000 cycles            |
| Dielectric strength.....                | 3000V, AC 50HZ, 1 minute |
| Insulation resistance.....              | ≥ 100MΩ                  |