

Data Sheet

Contactless switch

Version 04/22


Specification

Switch rating.....	300mA/6-24VDC
Head shape.....	Round head
Operation type.....	1NO momentary
LED colour.....	None/Red
Terminal.....	1.2m wire leading
Reaction distance.....	2-15cm
Operating and storage temperature.....	-15 to +55°C
Operating and storage humidity.....	45 to 85 % RH
Material.....	Stainless steel
Electrical lifetime.....	1,000,000 cycles
Dielectric strength.....	1500 VAC, 50 HZ, 1 minute
Insulation resistance.....	≥100MΩ


Item No.	Mounting Hole size	Product size (Ø)	Illumination type	LED voltage
2522768	19 mm	22 mm	Dot	6 - 24 VDC
2522769	22 mm	25 mm	Dot	6 - 24 VDC
2522770	22 mm	25 mm	Ring	12 - 24 VDC
2522771	25 mm	28 mm	Dot	6 - 24 VDC
2522772	25 mm	28 mm	Ring	12- 24 VDC
2522773	30 mm	35 mm	Dot	6 - 24 VDC
2522774	30 mm	35 mm	Ring	12 - 24 VDC

Data Sheet


Drawing for Item no. 2522768

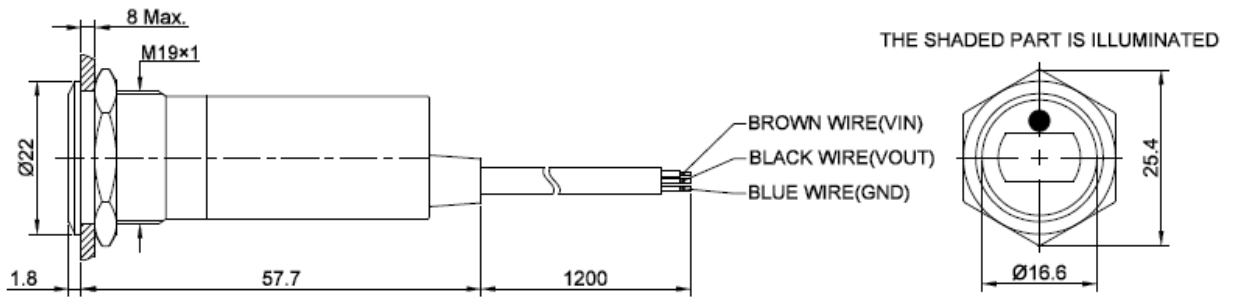


Drawing for Item no. 2522769

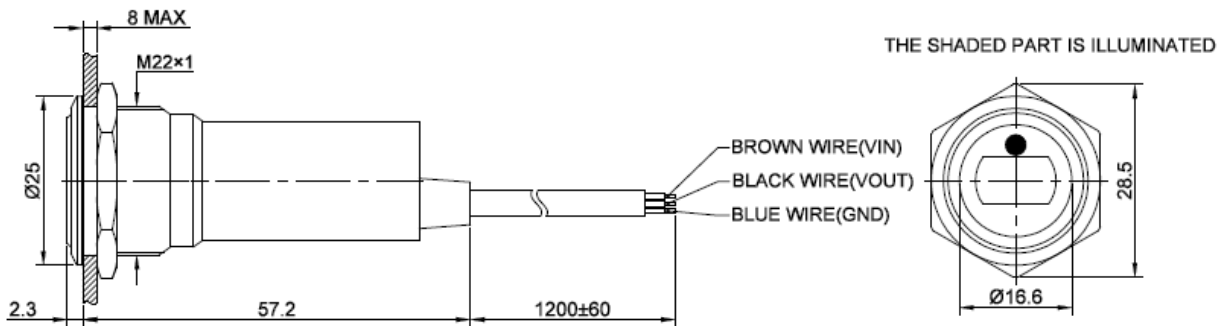

Drawing for Item no. 2522770

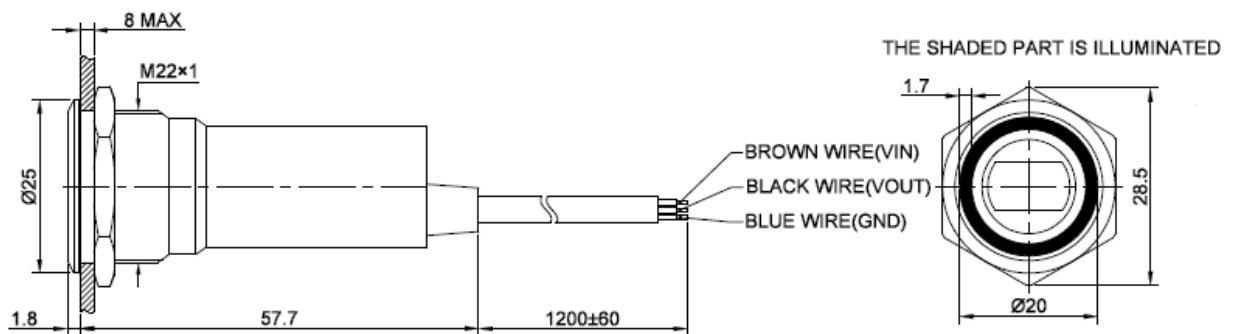


Drawing for Item no. 2522771

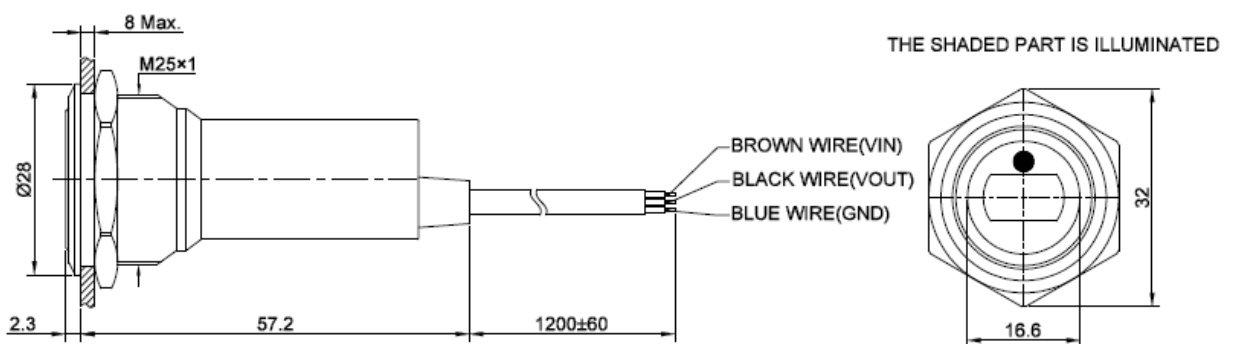


Data Sheet


Drawing for Item no. 2522772

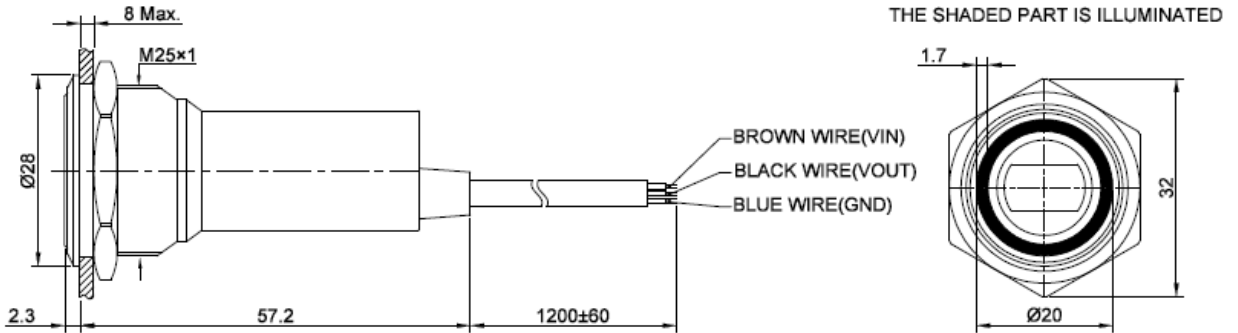

Drawing for Item no. 2522773

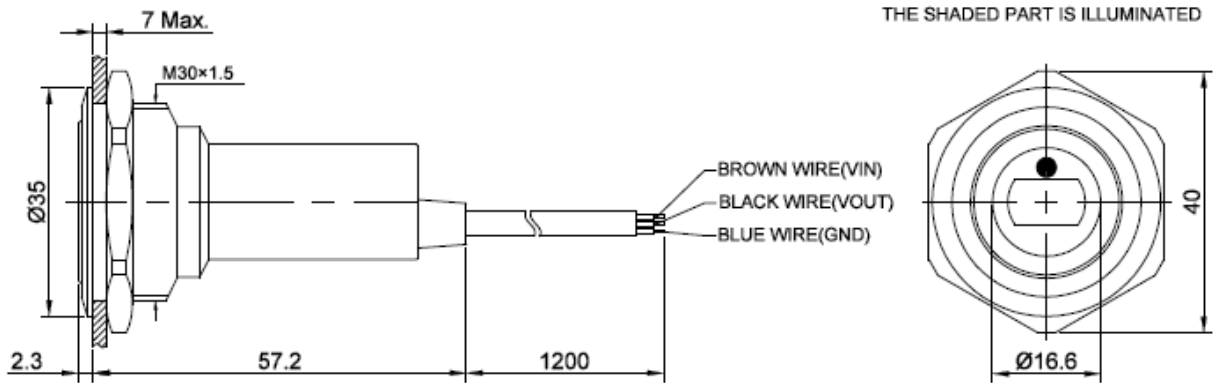

Drawing for Item no. 2522774

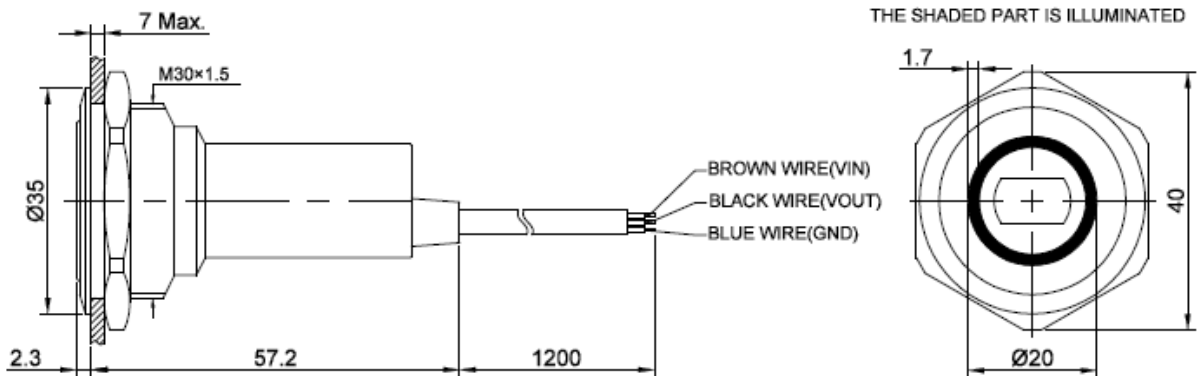

Data Sheet

Wiring instruction

