

Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau

Item no. 2522778

Data Sheet

Model:SU-CTC175S



175pcs Crimp Terminal Connector Assortment Set

Contents:


Section	Connector type	Stud size	ød2(mm)	B(mm)	L(mm)	F(mm)	ød1(mm)	Color	Qty. (pcs.)
1	Ring	M3	±0.2	±1.0	±1.0	±0.3	±0.2	Red	15
2		M4	±0.2	±1.0	±1.0	±0.3	±0.2		10
3		M5	±0.2	±1.0	±1.0	±0.3	±0.2		10
4		M3	±0.2	±1.0	±1.0	±0.3	±0.2		15
5		M4	±0.2	±1.0	±1.0	±0.3	±0.2	Blue	10
6		M5	±0.2	±1.0	±1.0	±0.3	±0.2		10
7		M5	±0.2	±1.0	±1.0	±0.3	±0.2	Yellow	5
8		M6	±0.2	±1.0	±1.0	±0.3	±0.2		5

Section	Connector type	Stud size	d2(mm)	B(mm)	L(mm)	F(mm)	ød1(mm)	Color	Qty. (pcs.)
9	Spade	M3	±0.2	±0.2	±1.0	±0.3	±0.2	Red	10
10		M4	±0.2	±0.2	±1.0	±0.3	±0.2		10
11		M4	±0.2	±0.2	±1.0	±0.3	±0.2	Blue	10

Section	Connector type	øB	L	øI	ød1	Color	Qty. (pcs.)
12	Butt	±0.2	±1.0	±0.5	±0.2	Red	10
13		5.9	24.5	15.0	1.7		
14		6.3	25.0	16.0	2.3	Blue	5
		8.3	24.8	15.0	3.4	Yellow	10

Section	Connector type	TAB	d2(mm)	T(mm)	L(mm)	F(mm)	ød1(mm)	Color	Qty. (pcs.)
15	Male	6.35 x 0.8	±0.2	±0.1	±1.0	±0.3	±0.2	Red	10
16		6.35 x 0.8	±0.2	±0.1	±1.0	±0.3	±0.2		10

Section	Connector type	Suitable for TAB	W(mm)	d2(mm)	L(mm)	F(mm)	ød1(mm)	Color	Qty. (pcs.)
17	Female	6.35 x 0.8	±0.2	±0.1	±1.0	±0.3	±0.2	Red	10
18		6.35 x 0.8	±0.2	±0.1	±1.0	±0.3	±0.2		10

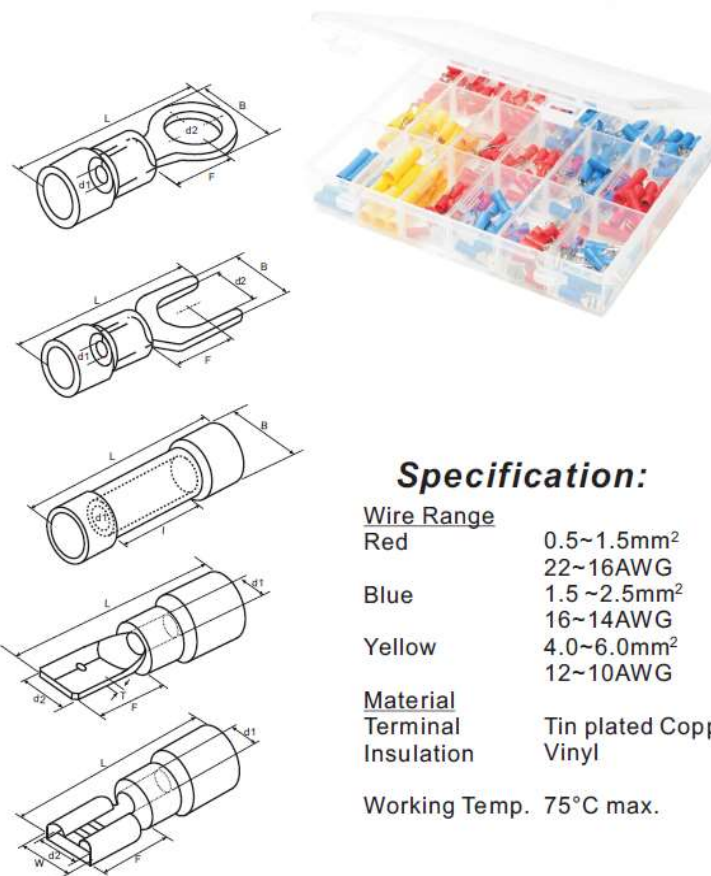

Specification:

Wire Range

Red	0.5~1.5mm ² 22~16AWG
Blue	1.5~2.5mm ² 16~14AWG
Yellow	4.0~6.0mm ² 12~10AWG

Material

Terminal	Tin plated Copper
Insulation	Vinyl

Working Temp. 75°C max.