

Model No.: **GP910A**


<b>NO MERCURY ADDED</b>	
<b>Description</b>	: Mercury Free Alkaline Manganese Battery, N Size
<b>Chemical System</b>	: Alkaline Manganese
<b>Nominal Voltage</b>	: 1.5 Volts
<b>Nominal Dimensions</b>	: $\phi$ 12.0 mm x 30.2 mm
<b>Terminals</b>	: Protruded positive (+) and flat negative (-) contacts
<b>Jacket</b>	: Foil jacket
<b>Applications</b>	: Hearing aid, pager, etc.
<b>Average Weight</b>	: 9g

### Cross References:



GP	JIS	IEC	Energizer	Duracell/
910A	LR1	LR1	E90	MN9100

### Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
20 Ohms	24 Hrs/ Day	0.9V	11.8 Hrs

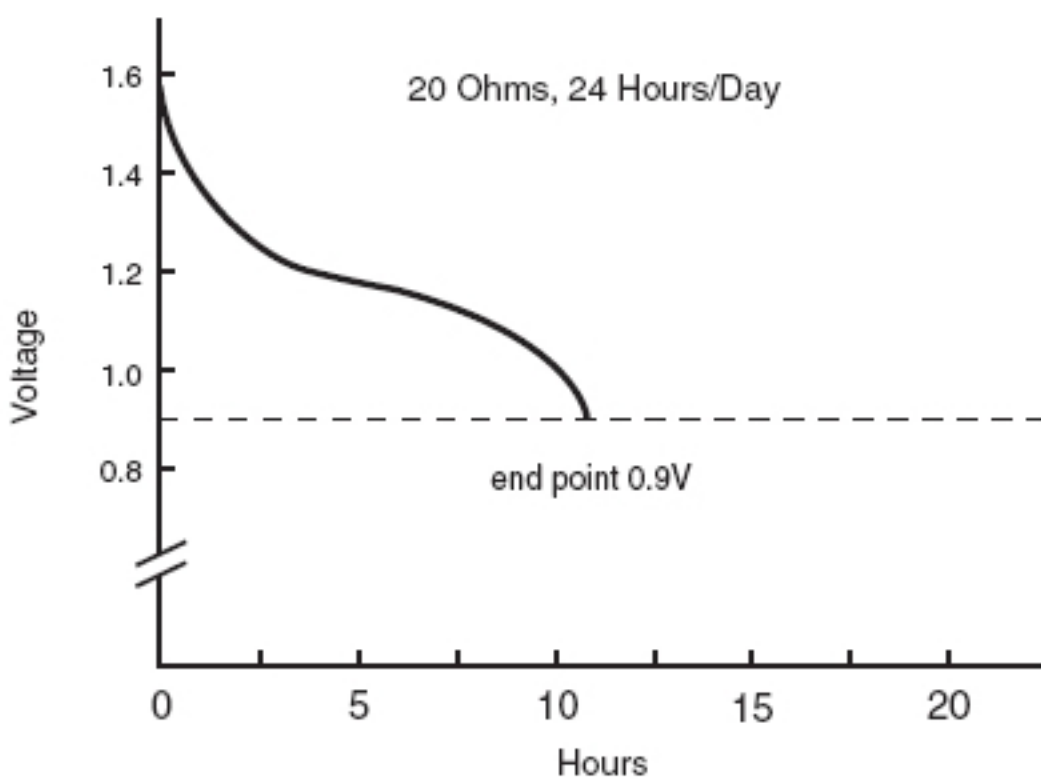

At 20°C±2°C within 30 days of manufacture

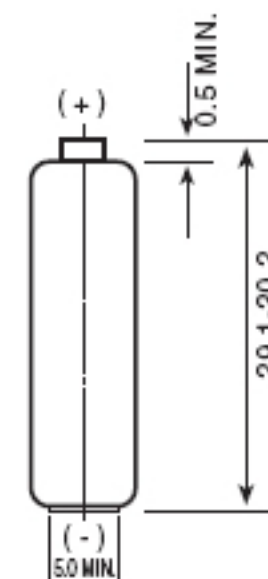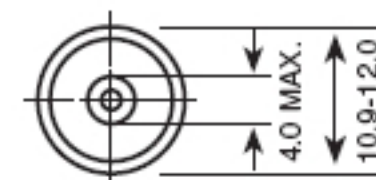

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

[www.gpbatteries.com](http://www.gpbatteries.com)

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.  
Copyright© GPI International Ltd, - All rights reserved

Member  
Gold Peak Group

11100110294