


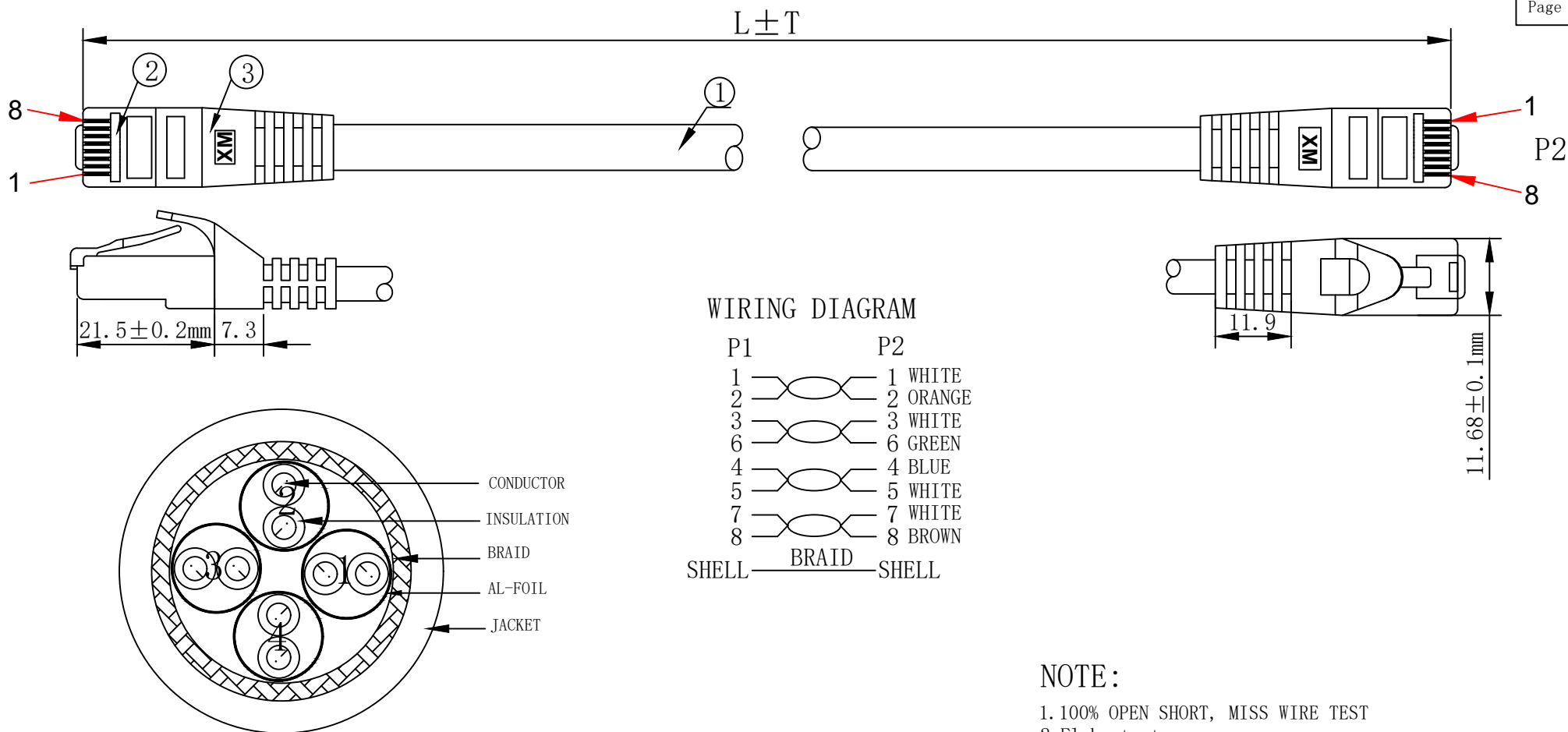

MATERIAL LIST

③	OVER MOLD	PVC(Color:SEE THE CHART)	2	
②	CONNECTOR	RJ45 8P8C Shielded Plug, Pin Gold Plated 3u", Shell Nickel plating Transparence blue	2	
①	CABLE	S/FTP CAT. 6A (AWG27 BC+AL-FOIL)*4PAIRS +BRAID JACKET:LSZH OD:5.8±0.2mm	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK
		ADD THE ITEM NO.		2022-07-14
		ADD THE ITEM NO.		2022-06-29
		NEW		2018-08-02
BY	CHK	REVISION RECORD MODIFICATION	DATE	REV.

NOTE:

- 100% OPEN SHORT, MISS WIRE TEST
- Fluke test :
TEST LIMIT:ISO 11801 Channel Class Ea
- PRINTING::CAT6A/Class Ea S/FTP 4x2x27AWG/7 LSZH ISO11801 & EN50173 & ANSI/TIA568.2-D
- RoHS 3.0 and REACH Compliant
- Working temperature:-10℃ ~ + 60℃
Storage temperature:-20℃~+75℃
Operation humidity:10%~85%
Storage humidity:10%~85%
- Packing:Renkforce Banderole

Renkforce						
CUSTOMER	CN	BN.	SEE THE CHART			
PRODUCT NAME	CAT. 6A S/FTP 27AWG			UNIT	MM	
DRAWN BY	CHECK BY	APPO BY	DATE			
Gao	ARVIN		2018-08-02			

CHART:

COLOR:GREY (RAL 7035)	
ITEM NO.	LENGTH
2522024	150 ⁻⁵ ₊₁₀ mm
2523755	250 ⁻⁵ ₊₁₀ mm
2523747	500 ⁻⁵ ₊₁₅ mm
2523746	1000±20mm
2523745	2000±30mm
2523744	3000±50mm
2523743	5000±100mm
2521974	10000±200mm
2521973	15000±300mm
2612328	20000±300mm
2595504	30000±300mm

COLOR:GREEN (Pantone 3278C)	
ITEM NO.	LENGTH
	150 ⁻⁵ ₊₁₀ mm
2582292	250 ⁻⁵ ₊₁₀ mm
2528208	500 ⁻⁵ ₊₁₅ mm
2528210	1000±20mm
	2000±30mm
2612329	3000±50mm
	5000±100mm
2612323	10000±200mm
2731199	15000±300mm
	20000±300mm
	30000±300mm

COLOR:WHITE (RAL 9003)	
ITEM NO.	LENGTH
2523727	150 ⁻⁵ ₊₁₀ mm
2521958	250 ⁻⁵ ₊₁₀ mm
2523726	500 ⁻⁵ ₊₁₅ mm
2521957	1000±20mm
2523725	2000±30mm
2521893	3000±50mm
2522018	5000±100mm
2521956	10000±200mm
2523724	15000±300mm
2731198	20000±300mm
	30000±300mm

COLOR:BLACK (Pantone Black 3C)	
ITEM NO.	LENGTH
2521969	150 ⁻⁵ ₊₁₀ mm
2523741	250 ⁻⁵ ₊₁₀ mm
2523740	500 ⁻⁵ ₊₁₅ mm
2522021	1000±20mm
2523739	2000±30mm
2523738	3000±50mm
2523737	5000±100mm
2523736	10000±200mm
	15000±300mm
	20000±300mm
	30000±300mm

COLOR:RED (Pantone 199C)	
ITEM NO.	LENGTH
2521988	150 ⁻⁵ ₊₁₀ mm
2521987	250 ⁻⁵ ₊₁₀ mm
2522025	500 ⁻⁵ ₊₁₅ mm
2521986	1000±20mm
2521977	2000±30mm
2523749	3000±50mm
2521985	5000±100mm
2521976	10000±200mm
	15000±300mm
	20000±300mm
	30000±300mm

COLOR:BLUE (Pantone 647C)	
ITEM NO.	LENGTH
	150 ⁻⁵ ₊₁₀ mm
2523728	250 ⁻⁵ ₊₁₀ mm
2522488	500 ⁻⁵ ₊₁₅ mm
2522019	1000±20mm
2523750	2000±30mm
2523729	3000±50mm
2523730	5000±100mm
2521959	10000±200mm
2521960	15000±300mm
2528209	20000±300mm
2616755	30000±300mm

COLOR:YELLOW (Pantone 135C)	
ITEM NO.	LENGTH
2623313	150 ⁻⁵ ₊₁₀ mm
2617816	250 ⁻⁵ ₊₁₀ mm
2612322	500 ⁻⁵ ₊₁₅ mm
2612325	1000±20mm
2544324	2000±30mm
2576834	3000±50mm
	5000±100mm
2576832	10000±200mm
	15000±300mm
	20000±300mm
	30000±300mm

Renkforce					
CUSTOMER	CN	BN.			
PRODUCT NAME	CAT. 6A S/FTP 27AWG			UNIT	MM
DRAWN BY		CHECK BY	APPO BY	DATE	
Gao		ARVIN		2018-08-02	