

EKP 80-T

Order symbol: EKP 80-T

Product nbr: 3720559

Description: Cover

Remarks: Transparent. PC


Including:

EAN: 6418074000354

El. number:

- Finland: 3420172
- Denmark: 8212007178
- Sweden: 2537916

Sample image

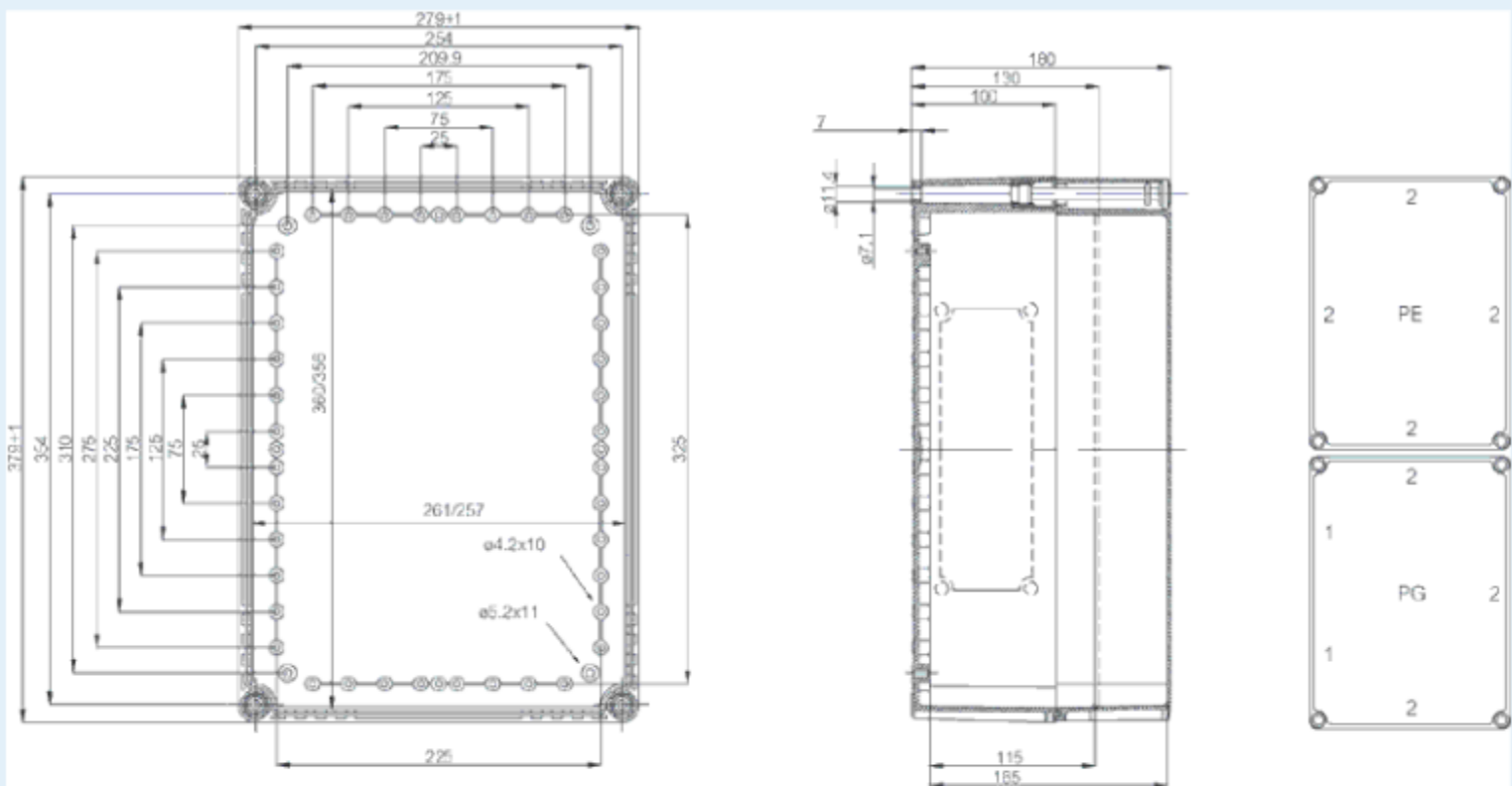

Dimensions:	Height	Width	Depth
mm:	380	280	80
inch:	14.96	11.02	3.15

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term): -40 ... 120

Temperature °C (continuous):

Temperature °F (short term): -40 ... 250

Temperature °F (continuous): -40 ... 175

Accessories:

EKV 32 DIN-35 Mounting rail. for enclosures:
(335 x 35 x 1)

EKV 22 DIN-35 Mounting rail. for enclosures:
(235 x 35 x 1)

EKPZR Extension frame. for enclosures:
(380 x 280 x 50)

EKPVT Back Panel. for enclosures:
(338 x 238 x 1)

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

Certificates:

SGSFIMKO_EK