

# EKP 80-G

**Order symbol:** EKP 80-G

**Product nbr:** 3730559

**Description:** Cover

**Remarks:** Opaque. PC


**Including:**

**EAN:** 64 18074000378

**El. number:**

- Finland: 3420173
- Denmark: 8212007194
- Sweden: 2537918

Sample image

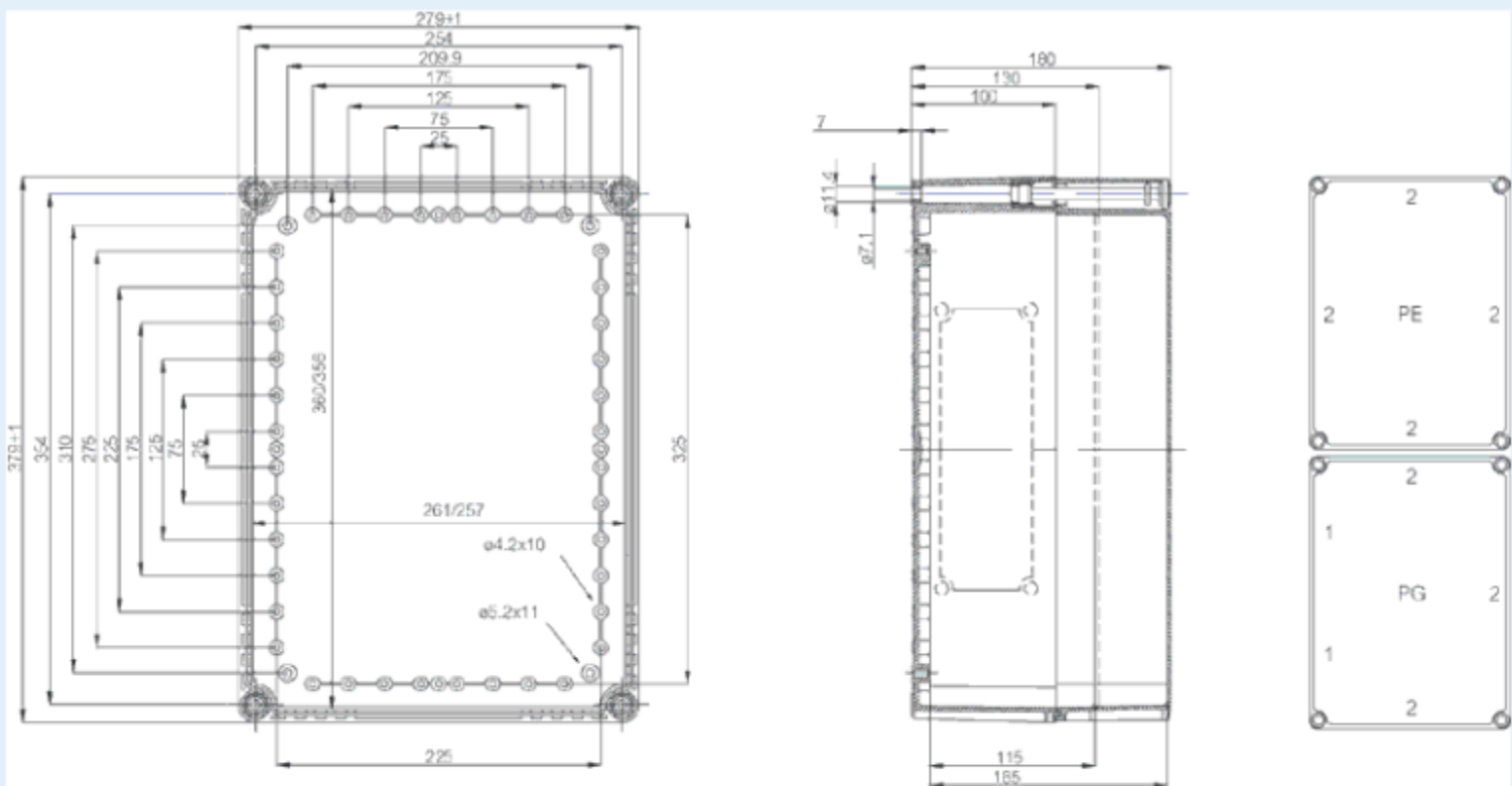

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
| mm:         | 380    | 280   | 80    |
| inch:       | 14.96  | 11.02 | 3.15  |

#### Materials:

Material:

Base colour:

Cover colour:

Gasket material:

#### Temperatures:

Temperature °C (short term): -40 ... 120

Temperature °C (continuous):

Temperature °F (short term): -40 ... 250

Temperature °F (continuous): -40 ... 175

#### Accessories:

EKV 32 DIN-35 Mounting rail. for enclosures:  
(335 x 35 x 1)

EKV 22 DIN-35 Mounting rail. for enclosures:  
(235 x 35 x 1)

EKPZR Extension frame. for enclosures:  
(380 x 280 x 50)

EKPVT Back Panel. for enclosures:  
(338 x 238 x 1)

#### Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

#### Certificates:

SGSFIMKO\_EK