

EKO 30-G

FIBOX
Enclosing innovations

Order symbol: EKO 30-G

Product nbr: 3730096

Description: Cover

Remarks: Opaque. PC


Including:

EAN: 64 18074000323

El. number:

- Finland: 3420166
- Denmark: 82 12007149
- Sweden: 2537864

Sample image

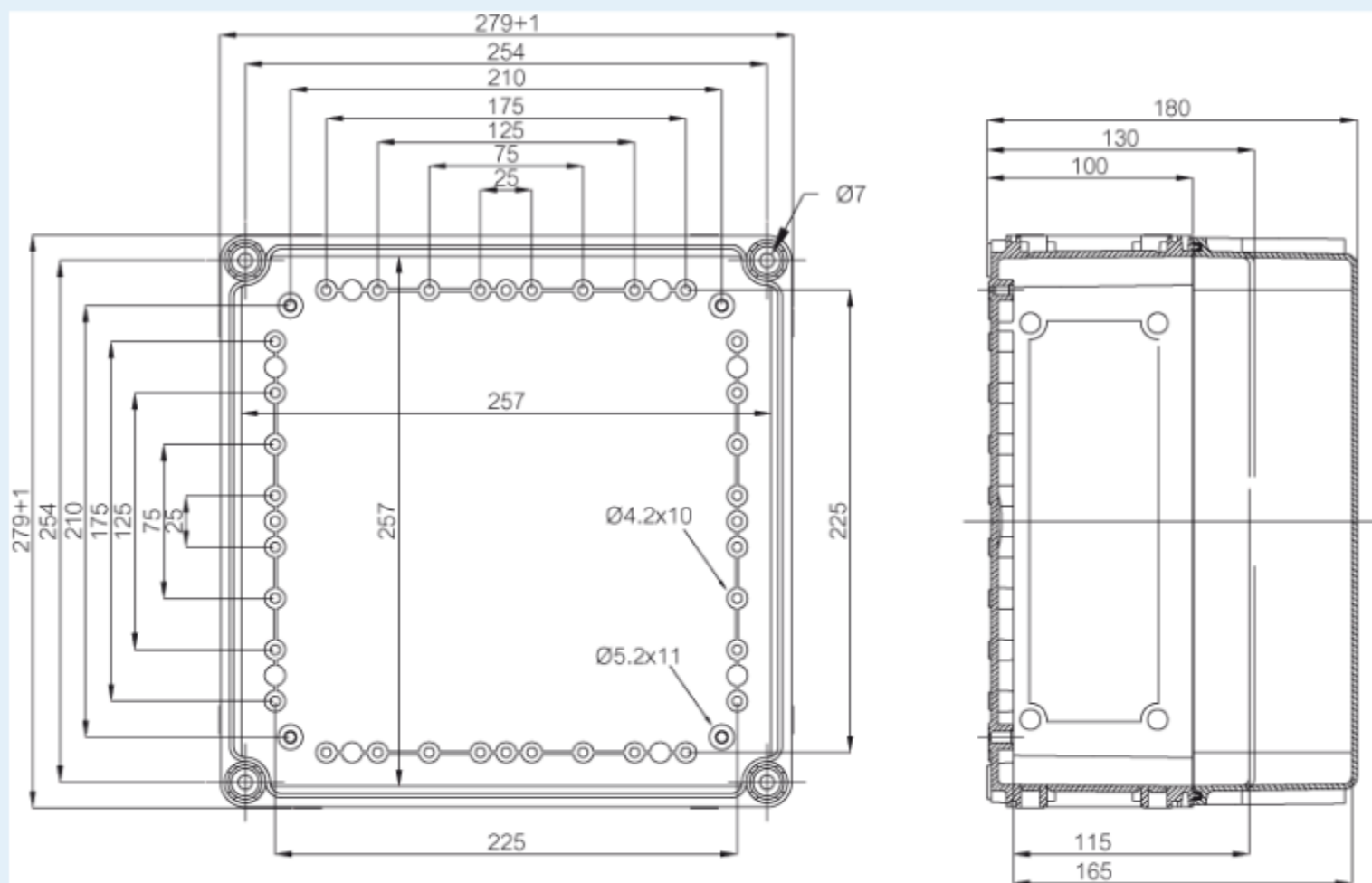

Dimensions:	Height	Width	Depth
mm:	280	280	30
inch:	11.02	11.02	1.18

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term): -40 ... 120

Temperature °C (continuous):

Temperature °F (short term): -40 ... 250

Temperature °F (continuous): -40 ... 175

Accessories:

EKOZR Extension frame. for enclosures:
(280 x 280 x 50)

EKV 22 DIN-35 Mounting rail. for enclosures:
(235 x 35 x 1)

EKOVT Back Panel. for enclosures:
(238 x 238 x 1)

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

Certificates:

SGSFIMKO_EK