

Order symbol: EKWH NEW

EAN: 64 18074042958

Product nbr: 3530907

El. number:


Description: Base. PC

- Finland: 3420316
- Denmark: 82 12006645
- Sweden: 2537830

Remarks: Base. PC Openings, 8x size 2 flange

Including:

Sample image

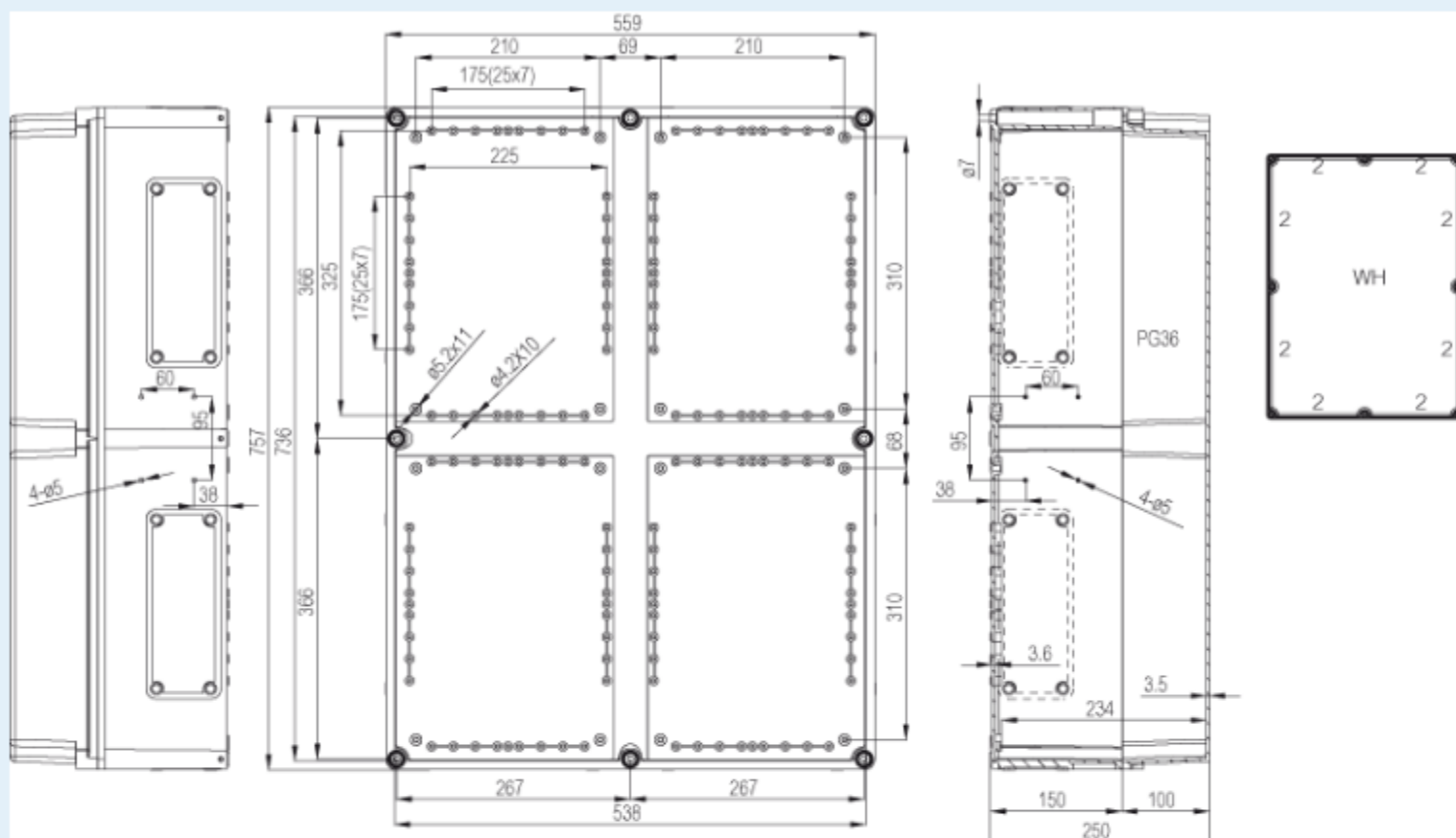

Dimensions:	Height	Width	Depth
mm:	760	560	150
inch:	29.92	22.05	5.91

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Accessories:

EKUVT Back Panel. for enclosures:
(518 x 338 x 1)

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

Certificates:

SGSFIMKO_EK