

PCTQ 233011

FIBOX
Enclosing innovations



Sample image

Order symbol: PCTQ 233011

Product nbr: 7022900

Description: Enclosure. PC


Remarks: Clear transparent cover
(quick-locking)

Including: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.


EAN: 6418074012340

El. number:

- Finland:
- Denmark:
- Sweden:

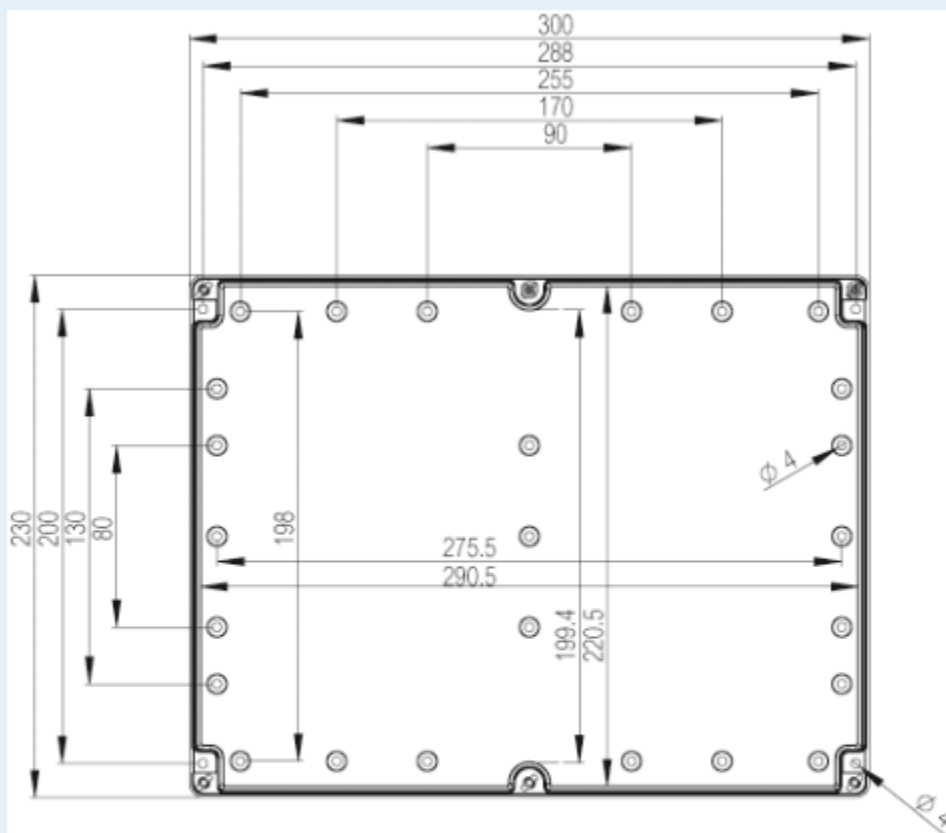

EU 233011 QR

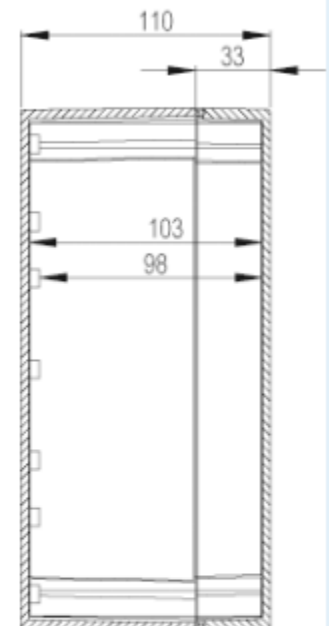

Dimensions:	Height	Width	Depth
mm:	230	300	110
inch:	9.06	11.81	4.33

Materials:

Material: Polycarbonate

Base colour:

Cover colour:

Gasket material: Polyurethane

Temperatures:

Temperature °C (short term): -40 ... 120

Temperature °C (continuous): -40 ... 80

Temperature °F (short term): -40 ... 250

Temperature °F (continuous): -40 ... 175

Accessories:

TF 28037 Mounting foot kit (4 pcs). for enclosures:

TRH 1216 DIN-15 Mounting rail. for enclosures:
(146 x 35 x 1)

TRH 2330 DIN-15 Mounting rail. for enclosures:
(285 x 35 x 1)

TRM 0816 DIN-15 Mounting rail. for enclosures:
(146 x 15 x 1)

TM 2330 Back Panel. for enclosures:
(221 x 274 x 1)

TH A Gray plastic hinges (2 pcs)

Rating:

Ingress protection (EN 60529): IP66; IP67;

Impact Resistance (EN 62262): IK07; IK08;

Electrical insulation: Totally insulated

Halogen free (DIN/VDE 0472, Part 815): 1

UV resistance: UL 508

Flammability Rating: UL 746C 5"

Glow Wire Test (IEC 695-2-1) °C: 960 °C

NEMA Class

Certificates:

SGSFimko_EURONORD