

# TPCM 191209T

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** TPCM 191209T

**Product nbr:** 5824029

**Description:** Enclosure. PC


**Remarks:** Clear transparent cover

**Including:**

**EAN:** 6418074087133

**El. number:**

- Finland:
- Denmark:
- Sweden:

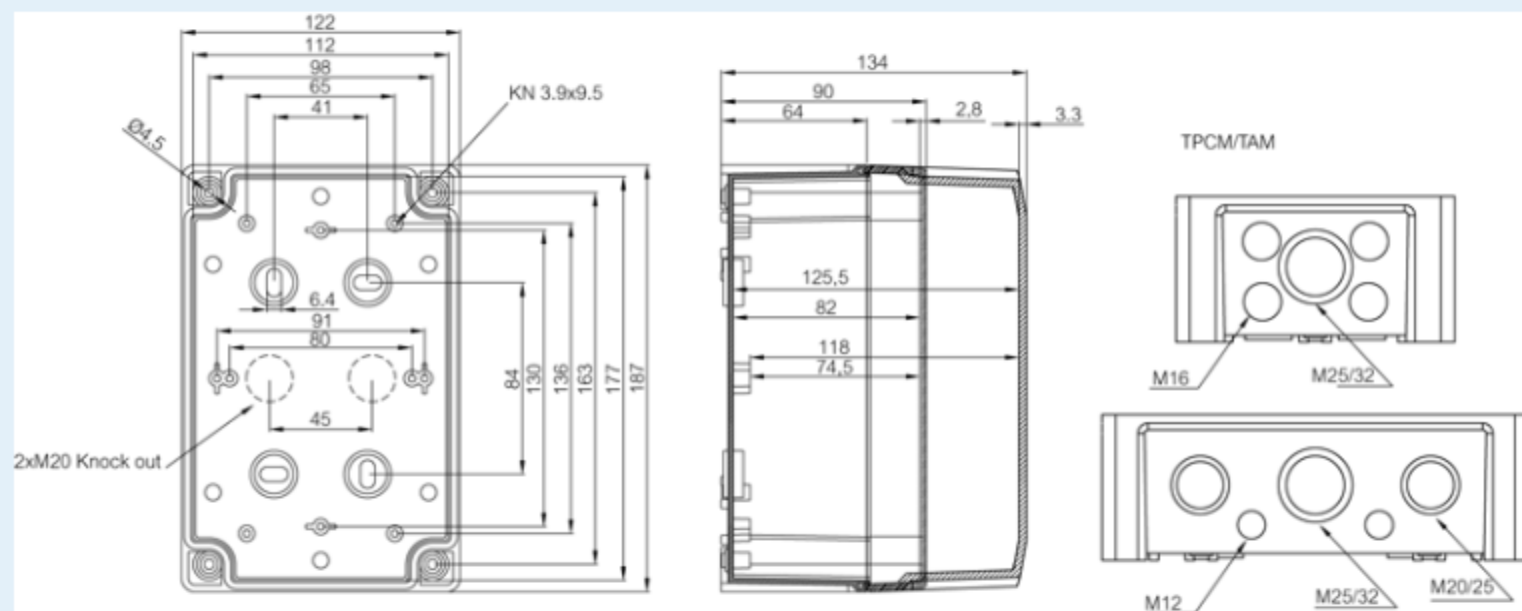

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
| mm:         | 187    | 122   | 90    |
| inch:       | 7.36   | 4.8   | 3.54  |

#### Materials:

Material: Polycarbonate

Base colour:

Cover colour:

Gasket material:

#### Temperatures:

Temperature °C (short term): -40 ... 120

Temperature °C (continuous):

Temperature °F (short term): -40 ... 250

Temperature °F (continuous): -40 ... 175

#### Accessories:

MIV 10 DIN-35 Mounting rail. for enclosures:  
(100 x 35 x 1)

MP 1912 Mounting plate. for enclosures:

DH-3 DIN-35 Mounting rail. for enclosures:  
(140 x 35 x 1)

FP 10674 Mounting foot kit (2 pcs) incl. screws

#### Rating:

Ingress protection (EN 60529): IP65;

Impact Resistance (EN 62262): IK07; IK08;

Electrical insulation: Totally insulated

Halogen free (DIN/VDE 0472, Part 815): 1

UV resistance: -

Flammability Rating: UL 746C 5"

Glow Wire Test (IEC 695-2-1) °C: 960 °C

NEMA Class

#### Certificates:

Certificate FI 40343