

TPC 342912

FIBOX
Enclosing innovations



Sample image

Order symbol: TPC 342912

Product nbr: 5824004

Description: Enclosure. PC



Remarks: Opaque cover

Including:

EAN: 6418074086877

El. number:

- Finland:
- Denmark:
- Sweden:

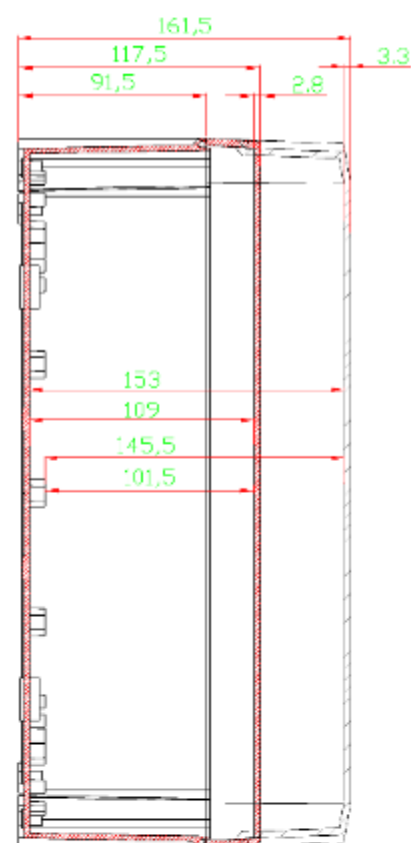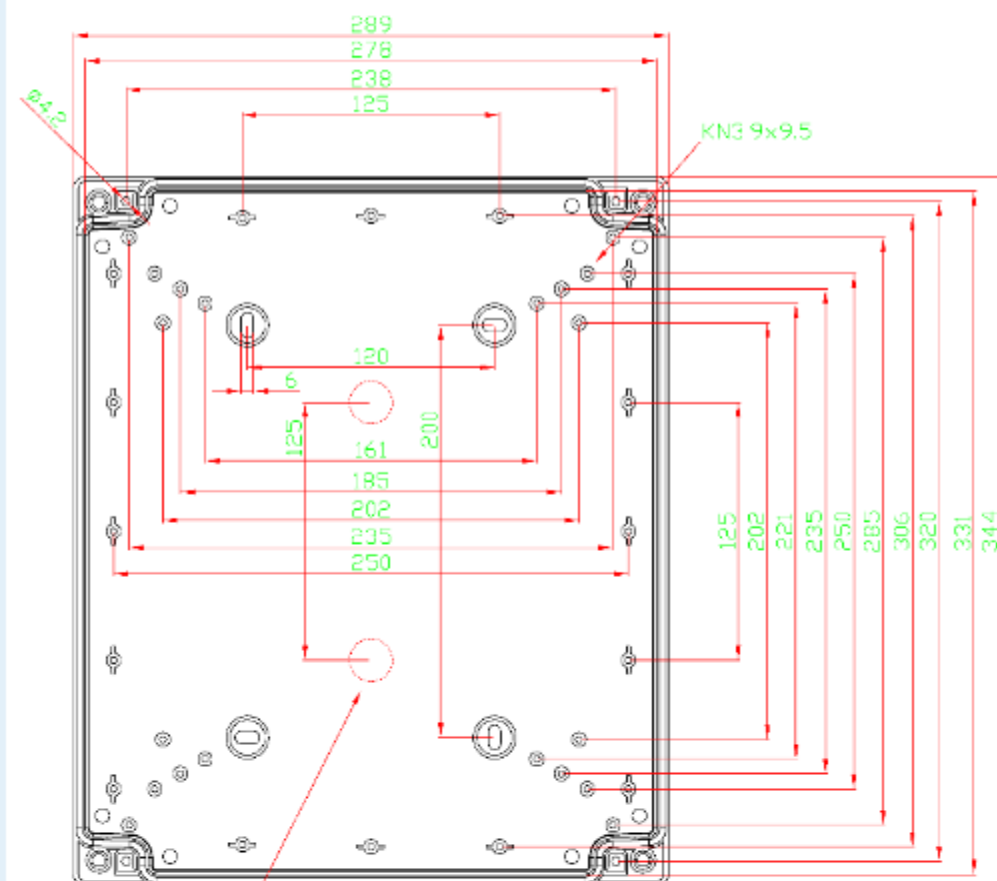

2xM20 knock out

Dimensions:	Height	Width	Depth
mm:	344	289	117
inch:	13.54	11.38	4.61

Materials:

Material: Polycarbonate

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term): -40 ... 120

Temperature °C (continuous):

Temperature °F (short term): -40 ... 250

Temperature °F (continuous): -40 ... 175

Accessories:

MP 3429 Mounting plate, for enclosures:

ARH 2328 DIN-35 Mounting rail, for enclosures:
(260 x 35 x 1)

FP 10674 Mounting foot kit (2 pcs) incl. screws

DR 316 DIN-35 Mounting rail, for enclosures:
(316 x 35 x 1)

Rating:

Ingress protection (EN 60529): IP65;

Impact Resistance (EN 62262): IK07; IK08;

Electrical insulation: Totally insulated

Halogen free (DIN/VDE 0472, Part 815): 1

UV resistance: -

Flammability Rating: UL 746C 5"

Glow Wire Test (IEC 695-2-1) °C: 960 °C

NEMA Class

Certificates:

Certificate FI 40343