

TPC 241911



Sample image

Order symbol: TPC 241911

Product nbr: 5824002

UL Code: 5854002

UL Name: UL TPC 241911

Description: Enclosure. PC



Remarks: Opaque cover

Including:

EAN: 6418074078780

EI. number:

- Finland:
- Denmark:
- Sweden:

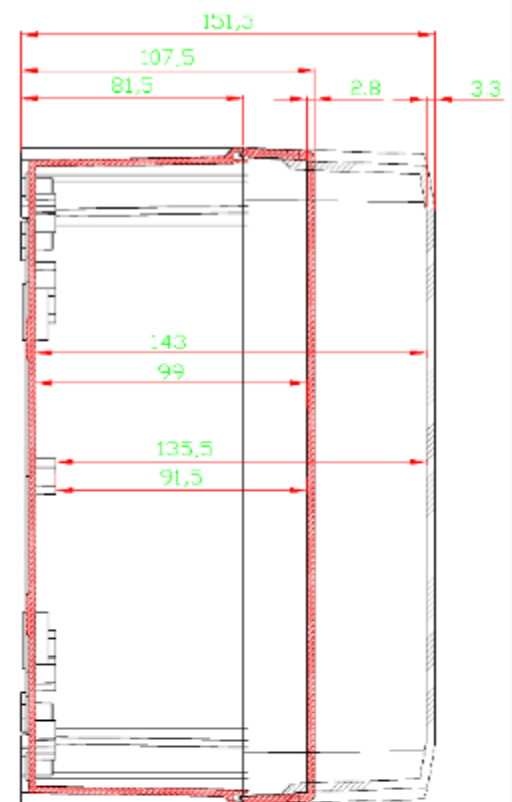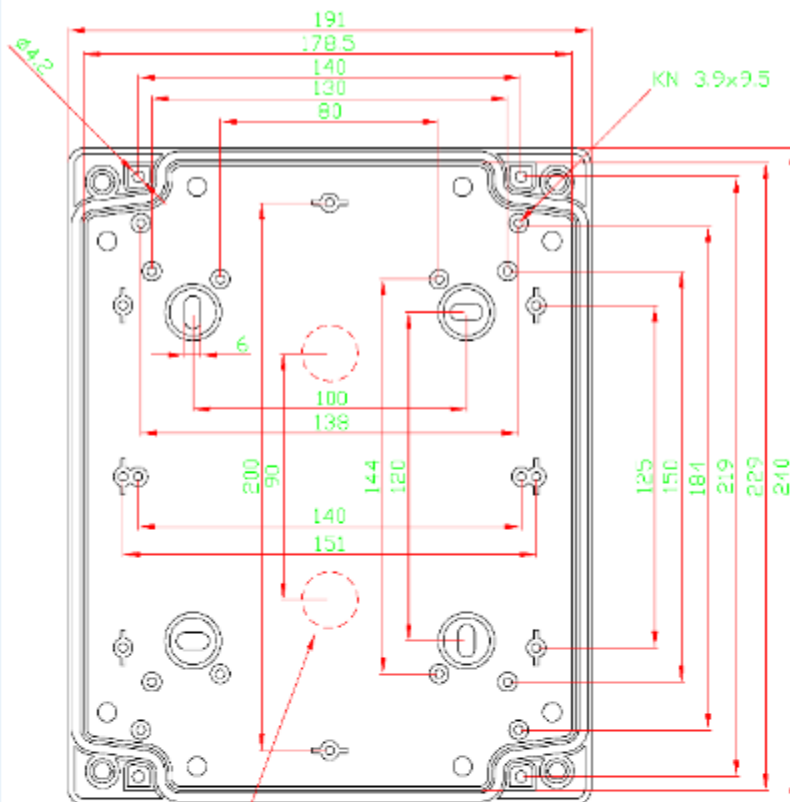

Dimensions:	Height	Width	Depth
mm:	240	191	107
inch:	9.45	7.52	4.21

Materials:

Material:	Polycarbonate
Base colour:	
Cover colour:	
Gasket material:	

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

MP 2419	Mounting plate. for enclosures:
EKV 12	DIN-35 Mounting rail. for enclosures: (160 x 35 x 1)
DR 210	DIN-35 Mounting rail. for enclosures: (210 x 35 x 1)
FP 10674	Mounting foot kit (2 pcs) incl. screws

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate FI 40343