

TPC 131007

FIBOX
Enclosing innovations



Sample image

Order symbol: TPC 131007

Product nbr: 5824040

Description: Enclosure. PC



Remarks: Opaque cover

Including:


EAN: 64 18074309563

El. number:

- Finland:
- Denmark:
- Sweden:

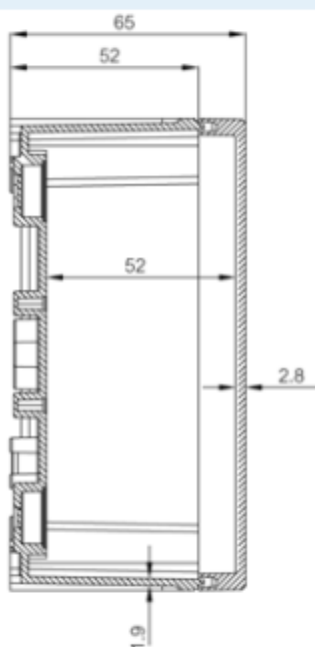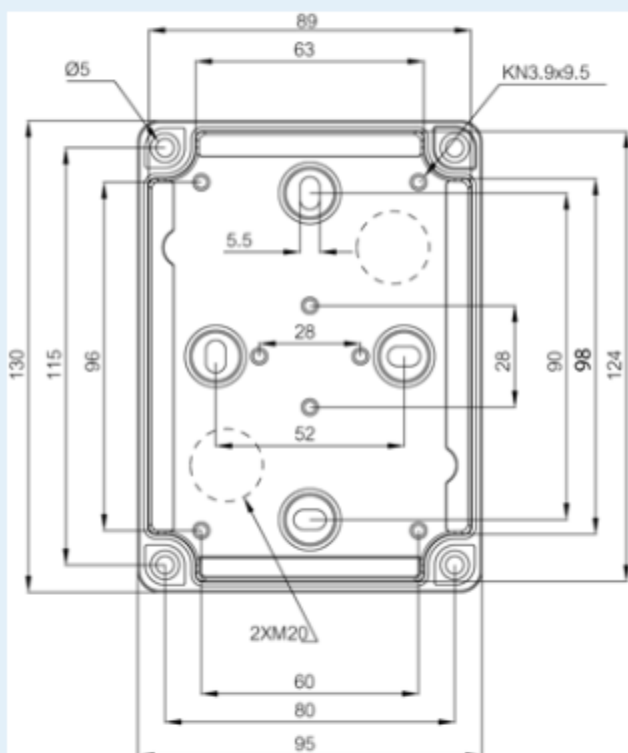


TPCM/TAM

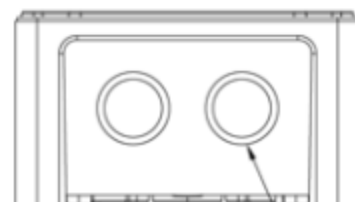

M20/M16

M20/M16

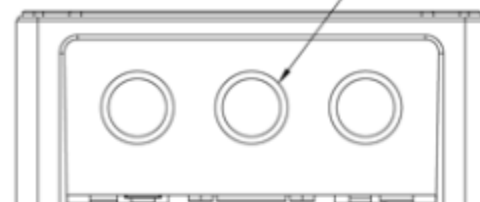

Dimensions:	Height	Width	Depth
mm:	130	95	65
inch:	5.12	3.74	2.56

Materials:

Material:	Polycarbonate
Base colour:	
Cover colour:	
Gasket material:	

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

FP 10674	Mounting foot kit (2 pcs) incl. screws
----------	--

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate FI 40343
