

TA292415



Sample image

Order symbol: TA292415

Product nbr: 5814053

Description: Enclosure. ABS


Remarks: Opaque cover

Including: Base with PUR gasket and screws for mounting plate/DIN-rail. cover with polyamide cover screws and plastic hinges.

EAN: 6418074309532

EI. number:

- Finland:
- Denmark: 8212097285
- Sweden:

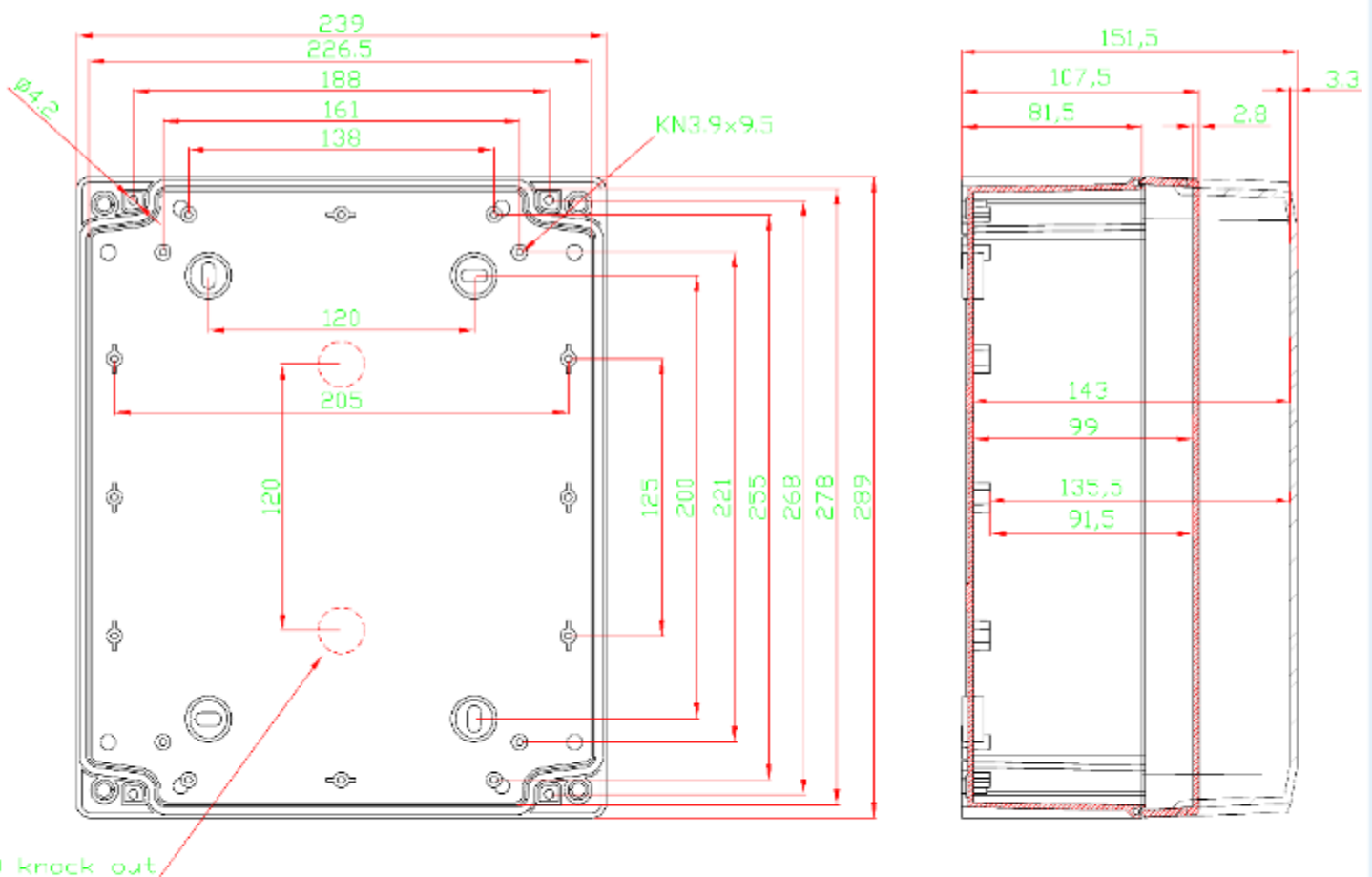

Dimensions:	Height	Width	Depth
mm:	289	239	150
inch:	0	0	0

Materials:

Material:	ABS
Base colour:	
Cover colour:	
Gasket material:	

Temperatures:

Temperature °C (short term):	-40 ... 80
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 175
Temperature °F (continuous):	-40 ... 140

Accessories:

MP 2924	Mounting plate. for enclosures:
DR 215	DIN-35 Mounting rail. for enclosures: (215 x 35 x 1)
DR 265	DIN-35 Mounting rail. for enclosures: (265 x 35 x 1)
FP 10674	Mounting foot kit (2 pcs) incl. screws

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C:	650 °C
NEMA Class	

Certificates:

Certificate FI 40343