


# MPP ARCA 6080

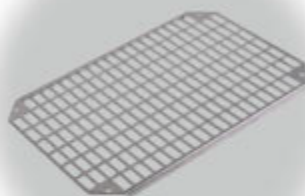

Sample image

**Order symbol:** MPP ARCA 6080

**Product nbr:** 8120935

**Description:** Mounting plate  
perforated (730x530x2 mm - 26x11  
mm)

**Remarks:** Galvanized steel. for size  
600x800x300

**Including:**

**EAN:** 6418074090478

**EI. number:**

- Finland:
- Denmark:
- Sweden:

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
|-------------|--------|-------|-------|

|     |   |   |   |
|-----|---|---|---|
| mm: | 0 | 0 | 0 |
|-----|---|---|---|

|       |   |   |   |
|-------|---|---|---|
| inch: | 0 | 0 | 0 |
|-------|---|---|---|

## Materials:

Material:

Base colour:

Cover colour:

Gasket material:

## Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

## Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

## Certificates: