


MPP ARCA 5070

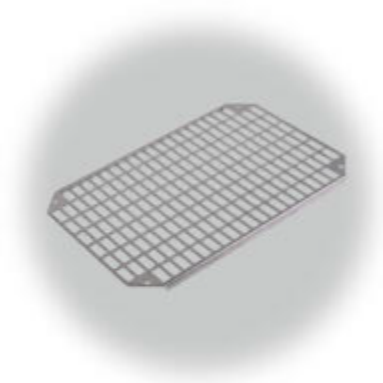

Sample image

Order symbol: MPP ARCA 5070

Product nbr: 8120934

Description: Mounting plate perforated (630x430x2 mm - 26x11 mm)

Remarks: Galvanized steel. for size 500x700x300

Including:

EAN: 6418074090461

El. number:

- Finland:
- Denmark:
- Sweden:

Dimensions:	Height	Width	Depth
-------------	--------	-------	-------

mm:	0	0	0
-----	---	---	---

inch:	0	0	0
-------	---	---	---

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Certificates: