


MPP ARCA 3040

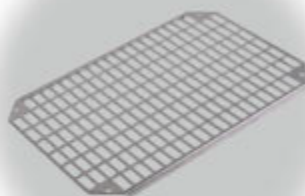

Sample image

Order symbol: MPP ARCA 3040

EAN: 6418074090430

Product nbr: 8120931

El. number:

Description: Mounting plate
perforated (350x250x2 mm -
26x11 mm)

- Finland:
- Denmark:
- Sweden:

Remarks: Galvanized steel. for sizes
300x400x150/210

Including:

Dimensions:	Length	Width	Height
mm:		0	0
inch:		0	0

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

NEMA Class

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Certificates: