

# PCT 162513



Sample image

**Order symbol:** PCT 162513

**Product nbr:** 7022861

**UL Code:** 7032861

**UL Name:** UL PCT 162513

**Description:** Enclosure. PC


**Remarks:** Clear transparent cover

**Including:** Base with screws for mounting plate/DIN-rail, cover with PUR gasket and stainless steel cover screws.

**EAN:** 6418074003812

**EI. number:**

- Finland: 3423542
- Denmark: 8212002979
- Sweden:

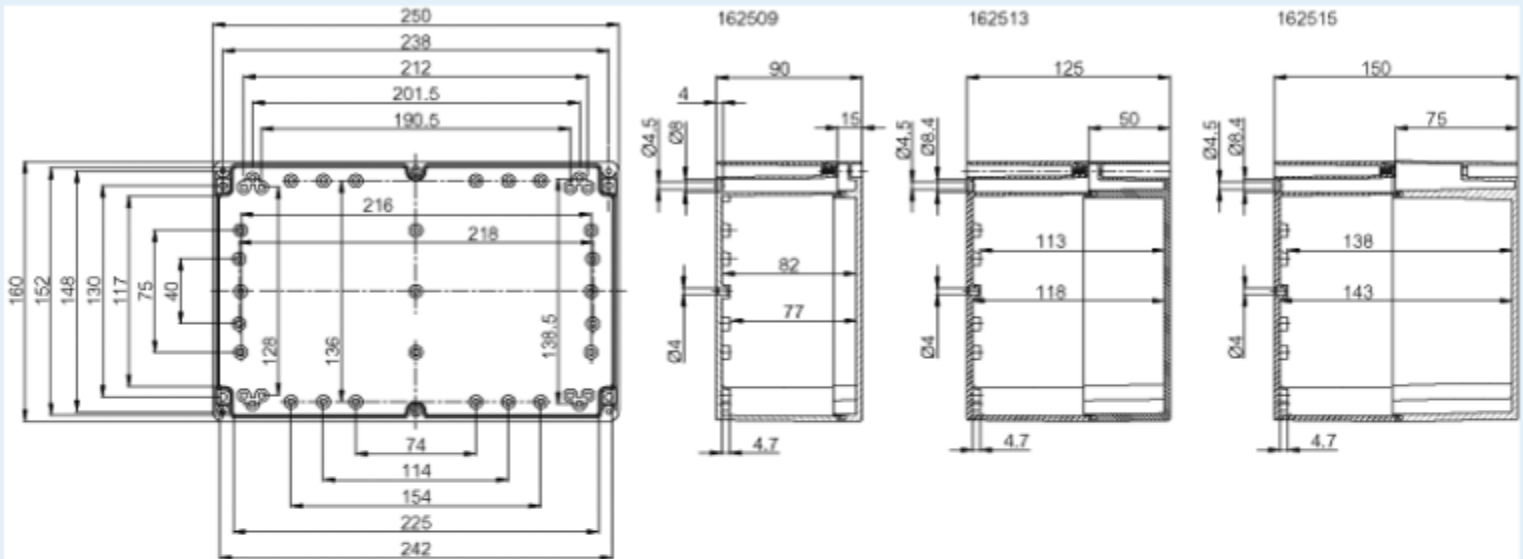

Dimensions:	Height	Width	Depth
mm:	160	250	125
inch:	6.3	9.84	4.92

#### Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### Accessories:

TM 1625	Back Panel. for enclosures: (151 x 214 x 1)
TRH 24	DIN-15 Mounting rail. for enclosures: (226 x 35 x 1)
TF 28037	Mounting foot kit (4 pcs). for enclosures:
TRH 1216	DIN-15 Mounting rail. for enclosures: (146 x 35 x 1)
TRM 0816	DIN-15 Mounting rail. for enclosures: (146 x 15 x 1)
TH A	Gray plastic hinges (2 pcs)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

SGSFimko\_EURONORD