

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

HR03 NI-MH 900 MAH (AAA) RECHARGEABLE BATTERY



Item No.:	Qty.
3205208	4
2525767	1


TECHNICAL DATA

Type:	AAA HR03
Classification:	Rechargeable
Chemical system:	Ni-MH
Nominal voltage:	1.2 V
Capacity	900 mAh
Weight	60 g
Operating conditions:	Charge: 0 to +40 °C Discharge: -20 to +55 °C Humidity: <65 % RH
Storage conditions:	-20 to +35 °C, <65 % RH


*For performance and safety, observe the operating / storage conditions.

DIMENSIONS

D	9.8-10.5mm
H	43.0-44.5mm
D1	3.7 ± 0.2mm
H1	1.7 ± 0.3mm

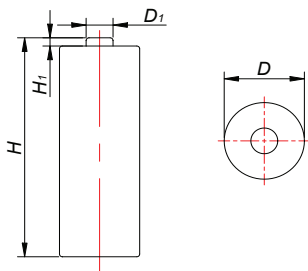

CHARGING CHARACTERISTICS

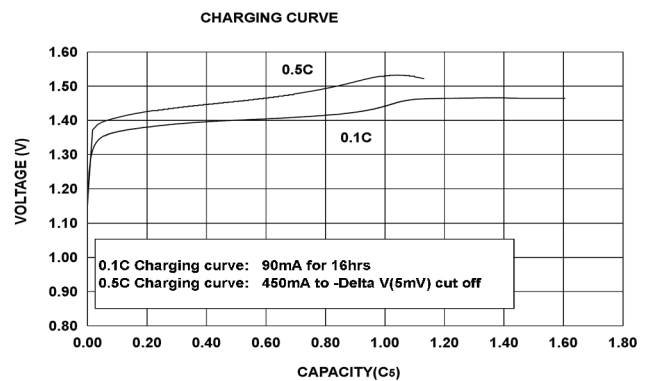

DISCHARGE CHARACTERISTICS

