

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

AA ALKALINE BATTERY



Item No.:	Qty.
2525873	1
2542830	4
2813277	10
2533752	24
2377792	40
2533739	50
3791584	100

TECHNICAL DATA



Type:	AA LR06
Classification:	Non-rechargeable
Chemical system:	Alkaline
Nominal voltage:	1.5 V
Terminals:	Flat
Weight (approx.):	24 g
Capacity	3200 mAh (10 mA, 24 h/d , 20 °C, e.v. = 0.8 V)
Operating conditions:	-18 to +50 °C +10 to +35 °C (recommended)
Storage conditions:	+10 to +25 °C (max. 30 °C), <60 % RH
Heavy metals:	No added mercury (Hg), Cadmium (Cd), or Lead (Pb)
Compliant to:	IEC 60086-1 IEC 60086-2 IEC 60086-5

*For performance and safety, observe the operating / storage conditions.




PERFORMANCE CHARACTERISTICS

DISCHARGE

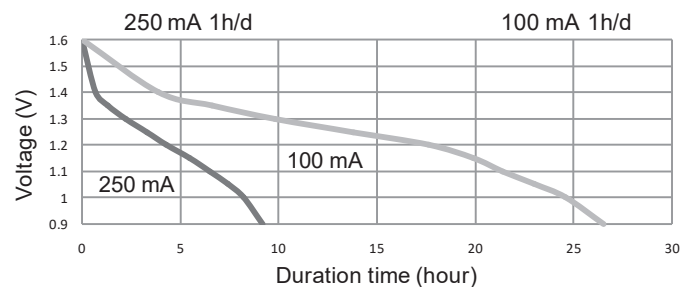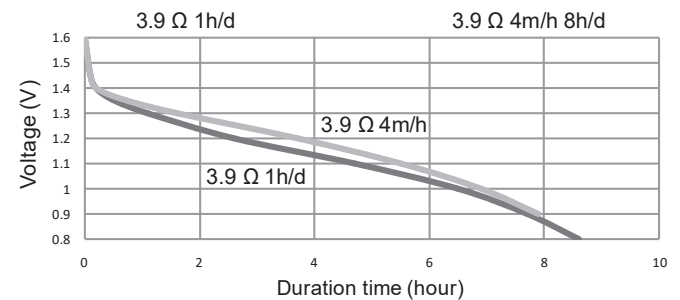

DIMENSIONS (mm)

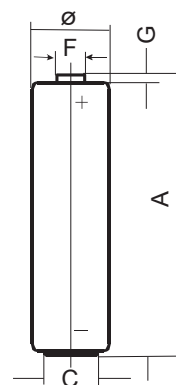

Dimension	Min.	Max.
Ø	13.7	14.5
A	49.5	50.5
C	7.0	-
F	-	5.5
G	1.0	-