

VOLTCRAFT

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

AA ALKALINE BATTERY



| Item No.: | Qty. |
|-----------|------|
| 2525873 | 1 |
| 2542830 | 4 |
| 2813277 | 10 |
| 2533752 | 24 |
| 2377792 | 40 |
| 3015478 | 50 |

TECHNICAL DATA



| | |
|-----------------------|---|
| Type: | AA LR06 |
| Classification: | Non-rechargeable |
| Chemical system: | Alkaline |
| Nominal voltage: | 1.5 V |
| Terminals: | Flat |
| Weight (approx.): | 24 g |
| Capacity | 3200 mAh (10 mA, 24 h/d, 20 °C, e.v. = 0.8 V) |
| Operating conditions: | -18 to +50 °C +10 to +35 °C (recommended) |
| Storage conditions: | +10 to +25 °C (max. 30 °C), <60 % RH |
| Heavy metals: | No added mercury (Hg), Cadmium (Cd), or Lead (Pb) |
| Compliant to: | IEC 60086-1 IEC 60086-2 IEC 60086-5 |

*For performance and safety, observe the operating / storage conditions.




PERFORMANCE CHARACTERISTICS

DISCHARGE

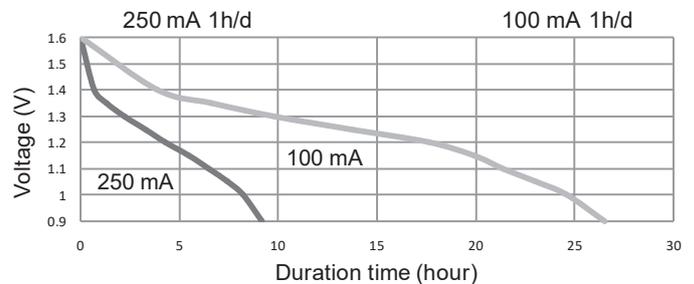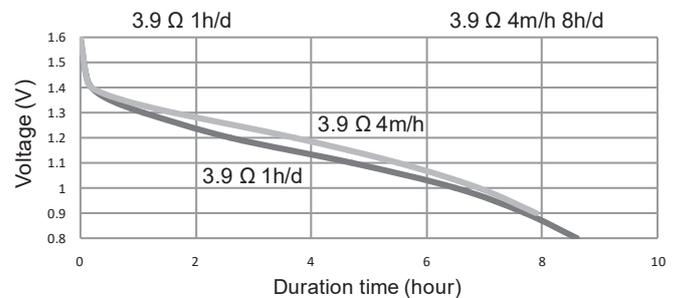

DIMENSIONS (mm)

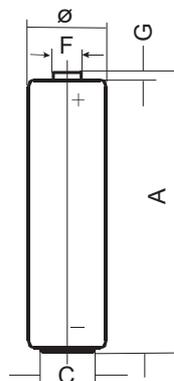

| Dimension | Min. | Max. |
|-----------|------|------|
| Ø | 13.7 | 14.5 |
| A | 49.5 | 50.5 |
| C | 7.0 | - |
| F | - | 5.5 |
| G | 1.0 | - |