

# **VOLTCRAFT**

## **DATASHEET**

Item No.: 2526462

Type designation: ER14505 Size: AA

Chemical system: Li/SOCl<sub>2</sub>


Nominal voltage: 3.6 V

Max weight: 19g

Max dimension: 14.5mm × 50.5mm

Measuring equipment shall be with a minimum accuracy of ±0.05mm

### **Cell Dimension: mm**

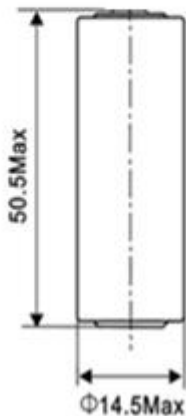

Nominal Capacity: 2400 mAh

Operating temperature: -55 °C ~ +50 °C

Recommended temperature: +10°C ~ +25°C

Recommend storage temperature: ≤30°C

Shelf lifetime: ≥10 Years

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing. Copyright 2023 by Conrad Electronic SE.

2526462\_v1\_0123\_02\_voltcraft\_ds