

# VOLTCRAFT

## DATASHEET

Item No.: 2533751

Type designation: ER14250 Size: 1/2AA

Chemical system: Li/SOC12


Nominal voltage: 3.6 V

Max weight: 10g

Max dimension: 14.5mm×25.5mm

Measuring equipment shall be with a minimum accuracy of  $\pm 0.05\text{mm}$

### Cell Dimension: mm

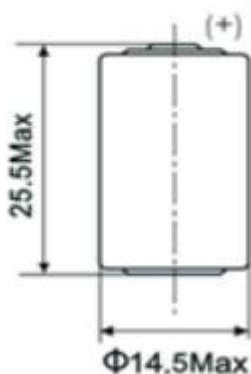

Nominal Capacity: 1200 mAh

Operating temperature:  $-55\text{ }^{\circ}\text{C} \sim +85\text{ }^{\circ}\text{C}$

Recommended temperature:  $+10\text{ }^{\circ}\text{C} \sim +25\text{ }^{\circ}\text{C}$

Recommend storage temperature:  $\leq 30\text{ }^{\circ}\text{C}$

Shelf lifetime:  $\geq 10$  Years

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau ([www.conrad.com](http://www.conrad.com)). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing. Copyright 2023 by Conrad Electronic SE.

2533751\_v1\_0123\_02\_voltcraft\_ds