

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

LITHIUM BATTERY 1200 MAH




TECHNICAL DATA

Item No.:	2533751	3451215
Packaging	1 pc/set	10 pcs/set
Type	Lithium LiSOC12 1/2 AA	
Classification	Non-rechargeable	
Terminal type	ER14250	
Nominal voltage	3.6 V	
Capacity	1200 mAh	
Max discharge current	15 mA (Continuity) 50 mA (Plus)	
Termination voltage	2.0 V	
CCV@330Ω	3.3 V	
Operation conditions	-40 to +85 °C, ≤65 % RH	
Storage conditions	+10 to +25 °C, ≤65 % RH	
Dimensions (H x Ø)	25.5 x 14.5 mm	
Weight (approx.)	10 g per pc	


*For performance and safety, observe the operating / storage conditions.

DIMENSIONS AND WEIGHT

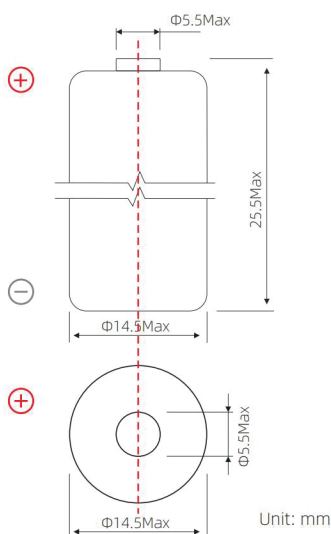


PERFORMANCE CHARACTERISTICS


Discharge characteristics

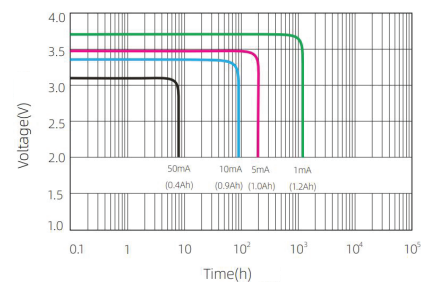

Voltcraft VS temperature

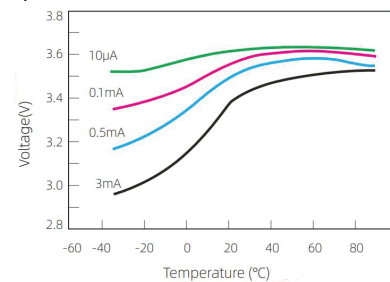

Capacity VS current

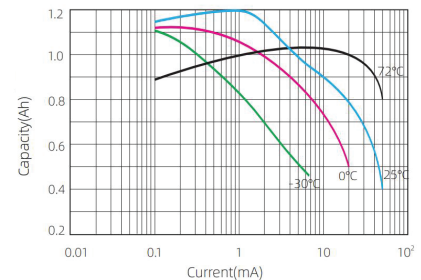

Storage characteristics

