

# VOLTCRAFT

## DATASHEET

Item No.: 2542801

Type designation: HR6 Common: AA

Chemical system: Ni-MH

Nominal voltage: 1.2 V


Weight: Approximate 21 g

Dimension (mm)

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Measuring equipment shall be with a minimum accuracy of  $\pm 0.05\text{mm}$ .

/	min	max
$\Phi$	13.7	14.5
A	49.5	50.5
C	7.0	-
F	-	5.5
G	1.0	-

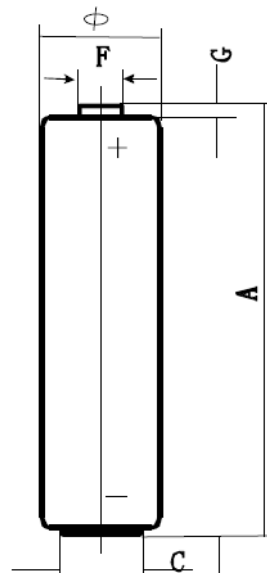

Capacity: 1100 mAh (11 mA, 24 h/d, 20°C, e.v.= 1.0 V)

Operating temperature: -20 °C ~ 55 °C

Recommend storage temperature:  $20 \pm 2^\circ\text{C}$

Shelf lifetime: 5 Years

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.  
Copyright 2023 by Conrad Electronic SE.

2542801\_v1\_1123\_02\_voltcraft\_ds