

VOLTCRAFT

DATASHEET

Item No.: 2542805

Type designation: HR6 Common: AA

Chemical system: Ni-MH

Nominal voltage: 1.2 V


Weight: Approximate 31 g

Dimension (mm)

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Measuring equipment shall be with a minimum accuracy of $\pm 0.05\text{mm}$.

/	min	max
Φ	13.7	14.5
A	49.5	50.5
C	7.0	-
F	-	5.5
G	1.0	-

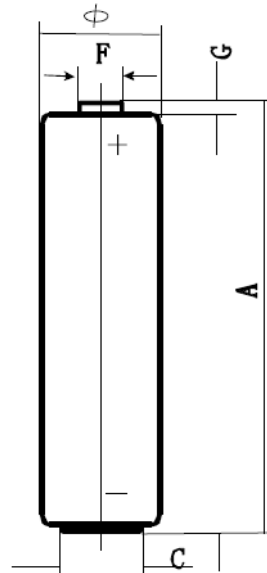

Capacity: 2750 mAh (27.5 mA, 24 h/d, 20°C, e.v.= 1.0 V)

Operating temperature: -20 °C ~ 55 °C

Recommend storage temperature: $20 \pm 2^\circ\text{C}$

Shelf lifetime: 5 Years