

DATASHEET

Item No.: 2542829

Type designation: LR03 Common: AAA

Chemical system: Alkaline


Nominal voltage: 1.5 V

Weight: Approximate 12.0 g

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Dimension (mm)

/	min	max
Φ	9.8	10.5
A	43.5	44.5
C	4.3	-
F	-	3.8
G	0.8	-

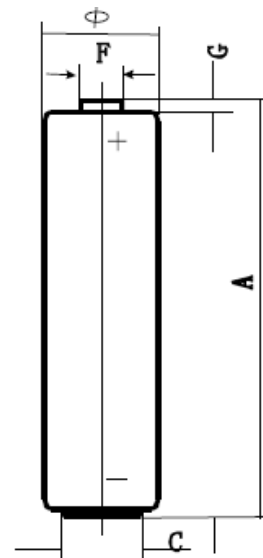

Capacity: 1350 mAh (10 mA, 24 h/d, 20°C, end voltage = 0.8 V)

Operating temperature: -18°C ~ 50°C

Recommend storage temperature: 20°C \pm 2°C

Shelf lifetime: 7 Years