

VOLTCRAFT

DATASHEET

Item No.: 2542831

Type designation: FR03 Common: AAA

Chemical system: Lithium


Nominal voltage: 1.5 V

Weight: Approximate 7.5 g

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Dimension (mm)

/	min	max
Φ	9.8	10.5
A	43.5	44.5
C	4.3	-
F	-	3.8
G	0.8	-

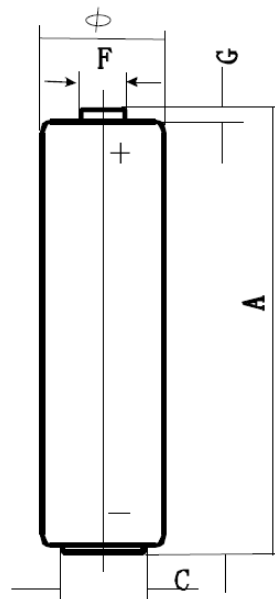

Capacity: 1100 mAh (30 mA, 24h/d, 23°C±2°C, e.v.= 0.9V)

Operating temperature: -30°C ~ 60°C

Recommend storage temperature: 20°C ± 2°C

Shelf lifetime: 10 Years

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.
Copyright 2023 by Conrad Electronic SE.

2542831_v1_1023_02_voltcraft_ds