

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.



LR43 BUTTON CELL ALKALINE


Item No.:	Pcs per pack
2542840	2
3221602	5

TECHNICAL DATA

Type:	LR43, AG12
Classification:	Non-rechargeable
Chemical system:	Lithium/Manganese Dioxide (Li/MnO ₂)
Nominal voltage:	1.5 V
Weight (approx.)	1.6 g
Capacity:	100 mAh
Loading:	10 kΩ (20 ±2 °C, 55 ±20 % RH)
Cut-off voltage:	1.2 V
Operating conditions:	-18 to +50 °C, 55 ±20 % RH recommended +10 to +35 °C
Storage conditions:	20 ± 2 °C, 55 ±20 % RH
Heavy metals:	No added mercury (Hg), Cadmium (Cd), or Lead (Pb)
Conforms to:	(EU) 2023/1542

For performance and safety, observe the operating / storage conditions. Capacity varies depending on the applied load, temperature, and cut-off voltage.

DIMENSIONS (mm)

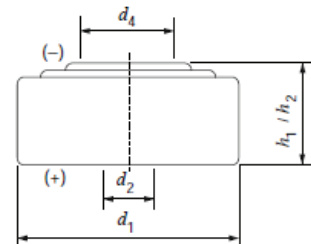

Dimension	LR43
h ₁ / h ₂	3.80 - 4.20
d ₁	11.25 - 11.60
d ₂	min. 3.80
d ₄	min. 3.80

