

# VOLTCRAFT

## DATASHEET

Item No.: 2542844

Type designation: CR-P2

Chemical system: Lithium/Manganese Dioxide (Li/MnO<sub>2</sub>)


Nominal voltage: 6.0 V

Weight: Approximate 37.0 g

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Dimension (mm)

/	min	max
Height	34.5	36.0
Width	32.5	35.0
Thickness	18.5	19.5

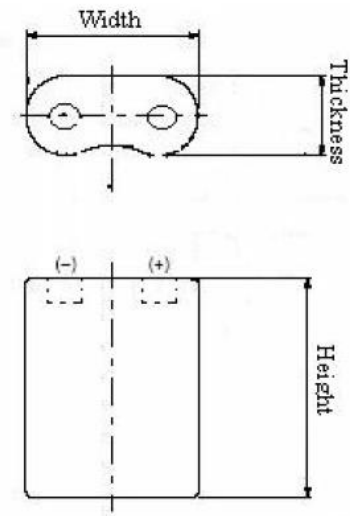

Capacity: 1400 mAh (10 mA, 24 h/d, 20°C, end voltage = 4.0 V)

Operating temperature: -40°C ~ 60°C

Recommend storage temperature: 20°C ± 2°C

Shelf lifetime: 10 Years