


RoHS Compliant

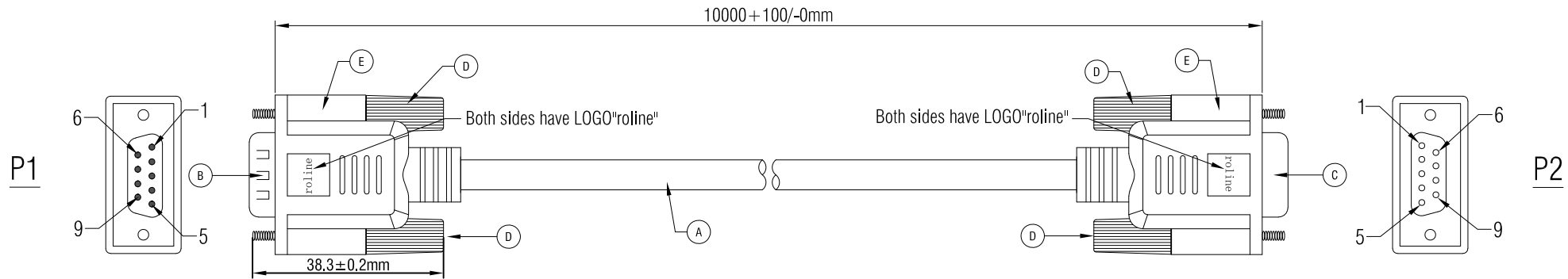

WIRE ADDRESS

P1	P2
1	1
2	2
3	3
4	4
5	5
6	6
7	7
8	8
9	9
Shell	Shell

Electrical Test:

- 1.100% TEST OPEN SHORT MIS-WIRE.
- 2.CONTACT RESISTANCE:10Ω MAX.
- 3.INSULATION RESISTANCE:5MΩ MIN.
- 4.HI-POT:300V DC/10MS.

E	45P PVC BEIGE		G	ROLINE RS232 Cable, DB9 M - F, 10 m SECOMP						
D	Screw: #4-40UNC 2.3*38.3mm(BEIGE MOLD NICKEL PLATED)	4	PCS							
C	DB 9P FEMALE(Black Insulator,Nickel Plated)	1	PCS				Item	11.01.6290		
B	DB 9P MALE(Black Insulator,Nickel Plated)	1	PCS				Draw	Kobe	Date: 2015.08.17	
A	NON-UL 30AWG*9C+AE,OD=5.0mm,BEIGE PVC JACKET.	1	PCS				Approval			
NUMBER	PRODUCT SPECIFICATIONS	Quantity	Unit				Duty	F16	BOM.NO: 10126	
1	2	4		Sample NO.	2016C42040A	Drawings of 1 (2)	Proportion: 1:1	Unit(mm)		A4



A4