


Product description M12-A connection cable male cable connector - female angled connector, Contacts: 5, unshielded, moulded cable, IP69K, UL, PUR black, 5 x 0.34 mm<sup>2</sup>, 3 m

Area M12-A series 763  
Part no. 77 3434 3429 50005-0300

## Illustration




## Scale drawing

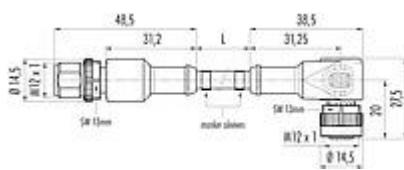

## Contact arrangement (Plug-in side)

 Stifteinsatz M12  
Male insert M12



Buchseinsatz M12  
Female insert M12



- 1 braun/brown
- 2 weiß/white
- 3 blau/blue
- 4 schwarz/black
- 5 grau/grey

## Technical data

### General features

Part no.	77 3434 3429 50005-0300
Connector design	connection cable male cable connector - female angled connector
Cable length	3 m
Version	connecting cable
Connector locking system	screw
Termination	moulded cable
Degree of protection	IP69K
Cross-sectional area	0.34 mm <sup>2</sup> / AWG 22
Temperature range from/to	-25 °C / 90 °C
Mechanical operation	> 100 Mating cycles
Weight (g)	120.00
Customs tariff number	85444290

### Electrical parameters

Rated voltage	60 V
Rated impulse voltage	1500 V
Rated current (40 °C)	4,0 A
Pollution degree	3
Overvoltage category	II
Insulating material group	II
EMC compliance	unshielded

Product description	M12-A connection cable male cable connector - female angled connector, Contacts: 5, unshielded, moulded cable, IP69K, UL, PUR black, 5 x 0.34 mm <sup>2</sup> , 3 m
Area	M12-A series 763
Part no.	77 3434 3429 50005-0300

### Material

Contact body material	PUR
Contact material	CuZn (brass) / CuSn (bronze)
Contact plating	Au (gold)
REACH SVHC	None (No pollutants)
SCIP number	SCIP-number not available

### Authorization/approvals

Approvals	UL
-----------	----

### Cable data - Structure of the cable

Cable diameter	5.0 mm
Cross section	5 x 0.34 mm <sup>2</sup>
Sheath material	PUR
Single-lead insulation	PP
Single-lead structure	42 x 0.10 mm
Cable color	black

### Cable data - Mechanical properties

Bending radius, fixed cable	≥ 5 x Ø
Bending radius, moving cable	≥ 10 x Ø
Bending cycles	>5 million
Permitted acceleration	5 m/s <sup>2</sup>
Travel speed	≤ 200 m/min (5 m horizontal distance)

### Cable data - Thermal properties

Temperature range cable in move from/to	-25 °C / 90 °C
Temperature range cable fixed from/to	-50 °C / 90 °C

Product description	<b>M12-A connection cable male cable connector - female angled connector, Contacts: 5, unshielded, moulded cable, IP69K, UL, PUR black, 5 x 0.34 mm<sup>2</sup>, 3 m</b>
Area	<b>M12-A series 763</b>
Part no.	<b>77 3434 3429 50005-0300</b>

### **General Disclaim Notice**

The connector must not be plugged or unplugged under load. Non-observance and improper use can result in personal injury.

The connectors have been developed for applications in plant engineering, control and electrical equipment construction. The user is responsible for checking whether the connectors can also be used in other areas of application.

The user must take suitable safety precautions to ensure that the connector cannot be accidentally disconnected.

Plug connectors with enclosure protection IP 67 and IP 68 are not suitable for use under water. For further information on the IP protection classes, please refer to the "Technical Information" download centre.

To lock the cable connector with the device connector, the threaded ring is tightened "hand-tight" (approx. 60 cNm).