


Data Sheet


Buzzer



1. Drawing

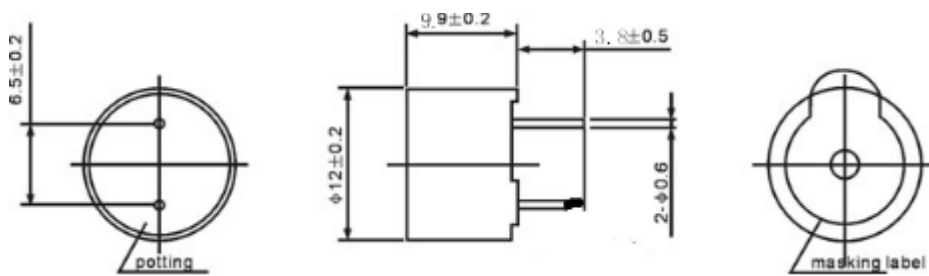

2. FREQUENCY RESPONSE [actual curve of type]

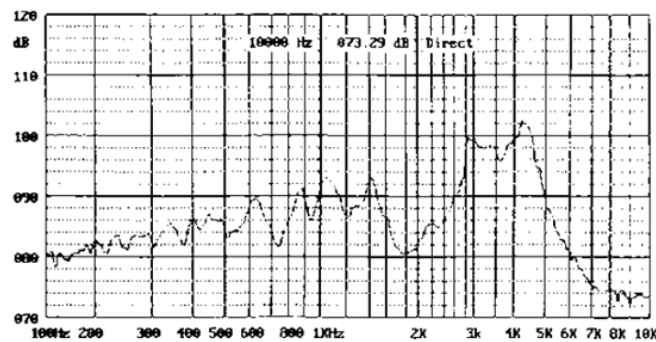

applied voltage: 1.5 v. 1/2 duty, square wave
distance for measurement: 10cm

Data Sheet

3. Technical data

No.	Item	Specification
1	Rated voltage	3V
2	Operating voltage	2-5V
3	Rated current	40mA
4	Coil Impedance	16 ± 4Ω
5	Min. S.P.L	85dB/10CM
6	Resonant Frequency	4000hz
7	Operating temperature	-20 to +70°C
8	Storage temperature	-30 to +80°C
9	Weight	2g

Remarks: It is a passive buzzer that requires an external driver circuit