

LogiLink®

USB-C™ 2-Port Wall Charger

1x USB-C™ Port & 1x USB Port

Art. No.: PA0212
PA0213



Portable designed for charging an USB-C™ laptop and a smartphone simultaneously. The perfect charging accessory for traveling.

Best Connectivity



RoHS
compliant



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China

LogiLink®

USB-C™ 2-Port Wall Charger

1x USB-C™ Port & 1x USB Port

Art. No.: PA0212
PA0213



1 Charger for 2 Devices

Charge your power-hungry devices with one 45 W or 65 W USB-C port and one 2.1 A fast charging USB-A port.



PA0212
USB-C 45W PD Port



PA0213
USB-C 65W PD Port



Multiple Protection

Supports overcurrent, overvoltage, overheating and short circuit protections.



RoHS
compliant



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China


Best Connectivity

LogiLink®

USB-C™ 2-Port Wall Charger

1x USB-C™ Port & 1x USB Port

Art. No.: PA0212
PA0213

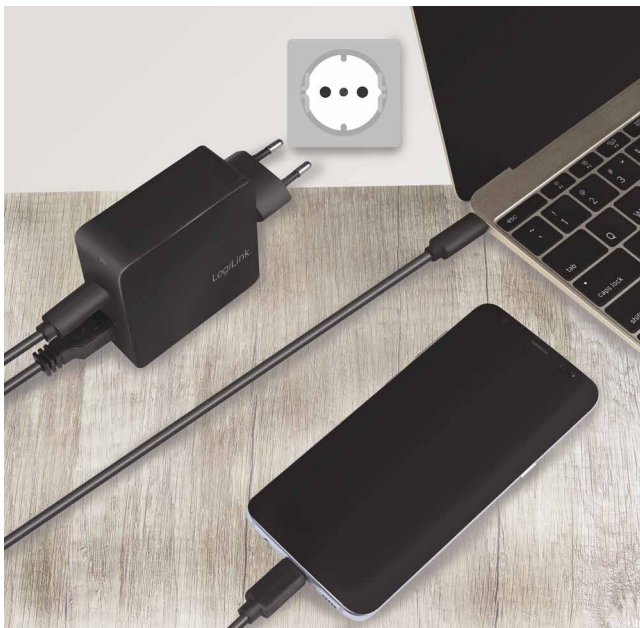

Simultaneous Charging

Charge 2 devices at the optimal speeds at the same time.



Wide Compatibility

Compatible with most mobile devices: smartphones, tablets, laptops and much more.

Best Connectivity



RoHS
compliant



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China

LogiLink®

USB-C™ 2-Port Wall Charger

1x USB-C™ Port & 1x USB Port



Art. No.: PA0212
PA0213

Specification:



45W
PA0212



65W
PA0213

Input	100–240 V AC 50/60 Hz 1 A max.	100–240 V AC 50/60 Hz 1 A max.
Output	USB-A port: 5V/2.1A (10.5W) max.	USB-A port: 5 V/2.1 A (10.5W) max.
Output	USB-C port: 5V/3A (15W), 9V/3A (27W), 12V/3A(36W), 15V/3A (45W), 20V/2.25A (45W) max.	USB-C port: 5V/3A (15W), 9V/3A (27W), 12V/3A(36W), 15V/3A (45W), 20V/3.25A (65W) max.
Protections	Overcurrent, overvoltage, overheating and short circuit	Overcurrent, overvoltage, overheating and short circuit
Efficiency	Level V	Level V
Operating Temperature Range	0–40°C	0–40°C
Storage Temperature Range	-40°C–85°C	-40°C –85°C
Relative Humidity	25% –90% (non-condensing)	25% –90% (non-condensing)
Dimension	100x61x29 mm	107x70x29 mm
Weight	116 g	175 g
EAN Code	4052792055115	4052792055122



RoHS
compliant



*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Made in China

LogiLink®

USB-C™ 2-Port Wall Charger

1 x USB-C™ Port & 1 x USB Port

Art. No.: PA0212
PA0213

Compatible Products from LogiLink:



Package Contents:

- » 1x USB Wall Charger
- » 1x User Manual

Package Information:

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
PA0212	176x127.5x42 mm	0.178 kg	445x390x275 mm	40 pcs	7.8 kg
PA0213	176x127.5x42 mm	0.23 kg	445x390x275 mm	40 pcs	9.9 kg



RoHS
compliant



⚠ Proper use of the PD function can only be guaranteed in combination with certified USB cables with E-Mark chipset.

*The specifications and pictures are subject to change without prior notice.

*All trade names referenced are the registered trademarks of their respective owners.

Made in China

Best Connectivity