

## 350pcs 3:1 Adhesive lined Heat shrink tube-assortment

Item No.: 1807CA006

This range is particularly suitable for hobbyists, craftsmen, field service, service workshops, electronics and the laboratory needs.


100 pieces of shrinking ration 3:1 standard shrinking tube for a range of application diameter from 1.6 to 12.7 mm.

Hot-melt adhesive lined tubing in the black color.

The heat-shrink tubing can be used for insulation, protective covering of components, as anti-kink protection, protection against corrosion, as well as repair of cables and lines, and much more be used.



Shrinking ratio	3 : 1
Material	PE
Shrinking temperature	90°C - 125 °C
Operation temperature	-40°C - 125 °C
Flammability	VW-1
Tensile strength	≥ 10,4 Mpa
Elongation at break	≥ 300%
Rated voltage	600V
Diselectric strength	≥ 1kv/mm at 30sec.
Volume resistivity	≥ 10 <sup>14</sup> Ω

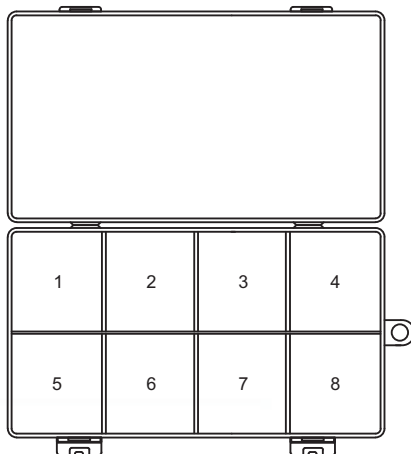

set contents

Section	Heat shrink tube		Length	pcs
	Inner diameter ø	after shrink ø		
1	1.6 mm	0.5 mm	60 mm	100
2	2.4 mm	0.8 mm	60 mm	80
3	3.2 mm	1.0 mm	60 mm	80
4	4.8 mm	1.6 mm	60 mm	45
5	6.4 mm	2.2 mm	60 mm	20
6	7.9 mm	2.7 mm	60 mm	10
7	9.5 mm	3.2 mm	60 mm	10
8	12.7 mm	4.2 mm	60 mm	5