

100pcs Heat shrink tube-assortment, shrink ratio 3:1

Item No.: 201711CA002

This range is particularly suitable for hobbyists, craftsmen, field service, service workshops, electronics and the laboratory needs.


100 pieces of shrinking ration 3:1 standard shrinking tube for a range of application diameter from 1.5 to 18 mm.

Thin wall tubing without internal adhesive in the Black color.

The heat-shrink tubing can be used for insulation, protective covering of components, as anti-kink protection, protection against corrosion, as well as repair of cables and lines, and much more be used.



Shrinking ratio	3 : 1
Material	PE
Shrinking temperature	70°C - 120°C
Operation temperature	-40°C - 120°C
Flammability	VW-1
Tensile strength	≥ 10.3Mpa
Elongation at break	≥ 300%
Rated voltage	600V
Diselectric strength	≥ 1kv/mm at 30sec.
Volume resistivity	≥ 10 ¹⁴ Ω

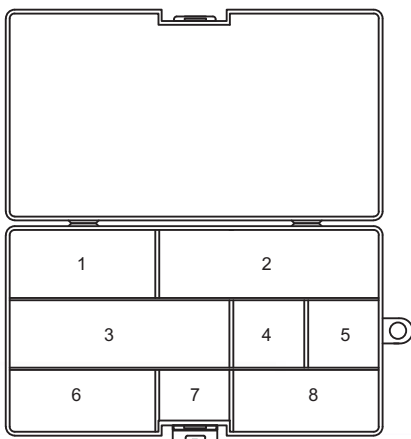

set contents

Section	Heat shrink tube		Length	pcs
	Inner diameter ø	after shrink ø		
1	12 mm	4 mm	65 mm	5
2	18 mm	6 mm	95 mm	3
3	15 mm	5 mm	95 mm	4
4	3 mm	1 mm	32 mm	25
5	1.5 mm	0.5 mm	32 mm	30
6	9 mm	3 mm	65 mm	8
7	4.5 mm	1.5 mm	32 mm	15
8	6 mm	2 mm	65 mm	10