

60pcs Plastic Cable Gland Set PG Thread, Black Item No. 2009CA105



Specification

Material:

Gland - PA 66

Seal - NBR

Color: Black (RAL9005)


Thread type: PG

Waterproof class: IP68

Working temperature: -20 ~ 80°C



* Washer and Locking Nut are including in set

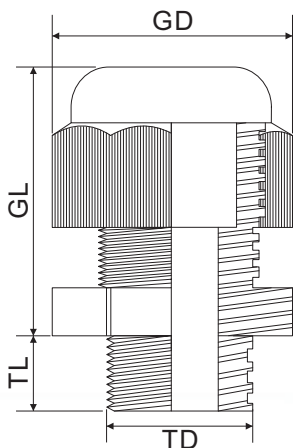

| Thread | Cable range (ømm) | TD (ømm) | TL (mm) | GL (mm) | GD (ømm) | Pcs. |
|--------|-------------------|----------|---------|---------|----------|------|
| PG7 | 3.0 ~ 6.5 | 12.5 | 9.0 | 20.2 | 17.0 | 15 |
| PG9 | 4.0 ~ 8.0 | 15.0 | 9.0 | 22.5 | 20.8 | 12 |
| PG13.5 | 6.0 ~ 12.0 | 20.1 | 9.0 | 26.5 | 25.9 | 10 |
| PG16 | 10.0 ~ 14.0 | 22.2 | 10.0 | 27.0 | 29.0 | 9 |
| PG21 | 13.0 ~ 18.0 | 28.0 | 12.0 | 30.6 | 35.8 | 8 |
| PG25 | 16.0 ~ 21.0 | 30.0 | 12.0 | 33.5 | 38.0 | 6 |