



224pcs Cable Gland Set, PG Thread, Grey

Item No. 2102CA111

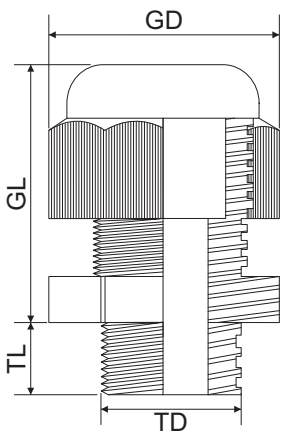

Thread	Cable range (ømm)	TD (ømm)	TL (mm)	GL (mm)	GD (ømm)	Pcs.
PG7	3.0 ~ 6.5	12.5	9.0	20.2	17.0	40
PG9	4.0 ~ 8.0	15.0	9.0	22.5	20.8	30
PG13.5	6.0 ~ 12.0	20.1	9.0	26.5	25.9	20
PG16	10.0 ~ 14.0	22.2	10.0	27.0	29.0	10
PG21	13.0 ~ 18.0	28.0	12.0	30.6	35.8	8
PG25	16.0 ~ 21.0	30.0	12.0	33.5	38.0	4

Thread	NH (mm)	Pcs.
PG7 X 1.5	4.80	40
PG9 X 1.5	4.90	30
PG13.5 X 1.5	5.00	20
PG16 X 1.5	5.80	10
PG21 X 1.5	6.30	8
PG25 X 1.5	6.70	4

 

Specification

Material:

Gland - PA 66

Seal - NBR

Color: Grey (RAL7035)

Thread type: PG

Waterproof class: IP68

Working temperature: -20 ~ 80°C