


## Plastic Cable Gland Set PG Thread

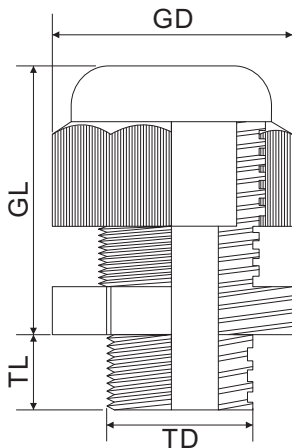

### Specification

**Material:**

**Gland - PA 66**

**Seal - NBR**

**Color:**

**Black (RAL9005)**

**Grey (RAL7035)**

**White (RAL 9010)**

**Thread type: PG**

**Waterproof class: IP68**

**Working temp.: -20 ~ 80°C**



\* Washer and Locking Nut are including in set

Item number	Thread	Cable range (ømm)	TD (ømm)	TL (mm)	GL (mm)	GD (ømm)	Color	Pcs.
2102CA117	PG7	3.0 ~ 6.5	12.5	9.0	20.2	17.0	Black	12
2102CA118	PG9	4.0 ~ 8.0	15.0	9.0	22.5	20.8	Black	8
2102CA119	PG13.5	6.0 ~ 12.0	20.1	9.0	26.5	25.9	Black	5
2102CA120	PG7	3.0 ~ 6.5	12.5	9.0	20.2	17.0	Grey	12
2102CA121	PG9	4.0 ~ 8.0	15.0	9.0	22.5	20.8	Grey	8
2102CA122	PG13.5	6.0 ~ 12.0	20.1	9.0	26.5	25.9	Grey	5
2102CA123	PG7	3.0 ~ 6.5	12.5	9.0	20.2	17.0	White	12
2102CA124	PG9	4.0 ~ 8.0	15.0	9.0	22.5	20.8	White	8
2102CA125	PG13.5	6.0 ~ 12.0	20.1	9.0	26.5	25.9	White	5