


## Plastic Cable Gland Set Metric Thread

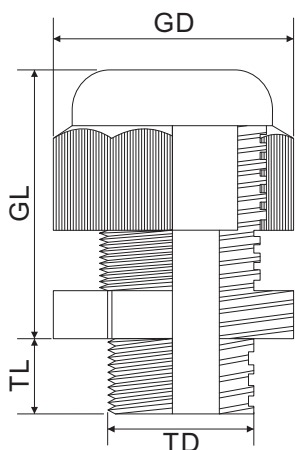

### Specification

**Material:**

**Gland - PA 66**

**Seal - NBR**

**Color:**

**Black (RAL9005)**


**Grey (RAL7035)**

**White (RAL 9010)**

**Thread type: Metric**

**Waterproof class: IP68**

**Working temp.: -20 ~ 80°C**

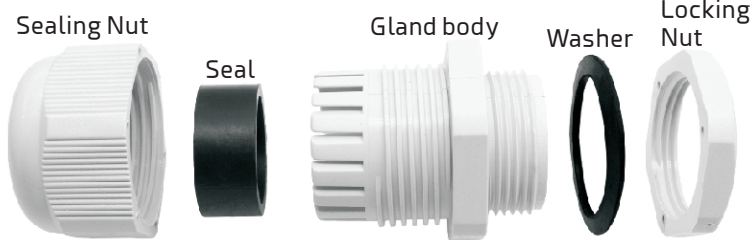

\* Washer and Locking Nut are including in set

Item number	Thread	Cable range (ømm)	TD (ømm)	TL (mm)	GL (mm)	GD (ømm)	Color	Pcs.
2102CA126	M 12	3.0 ~ 6.5	11.8	9.0	20.1	17.0	Black	12
2102CA127	M 16	4.0 ~ 8.0	15.7	9.0	23.5	20.8	Black	8
2102CA128	M 20	6.0 ~ 12.0	19.7	9.0	27.0	26.0	Black	5
2102CA129	M 12	3.0 ~ 6.5	11.8	9.0	20.1	17.0	Grey	12
2102CA130	M 16	4.0 ~ 8.0	15.7	9.0	23.5	20.8	Grey	8
2102CA131	M 20	6.0 ~ 12.0	19.7	9.0	27.0	26.0	Grey	5
2102CA132	M 12	3.0 ~ 6.5	11.8	9.0	20.1	17.0	White	12
2102CA133	M 16	4.0 ~ 8.0	15.7	9.0	23.5	20.8	White	8
2102CA134	M 20	6.0 ~ 12.0	19.7	9.0	27.0	26.0	White	5